


8-1735480-0 Product Details

[Share](#) |
 [Print](#) |
 [Email](#)

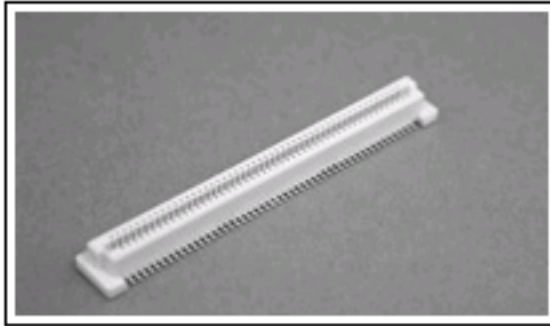

8-1735480-0

TE Internal Number: 8-1735480-0

Active

[View 3D PDF](#)

0.8mm Free Height

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Connector Style = Receptacle
- 200 Positions
- PCB Mounting Orientation = Vertical
- Board-to-Board Stack Height = 17.00 mm, 18.00 mm, 19.00 mm, 20.00 mm
- Gold (30) Contact Plating, Mating Area, Material

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [View Mating Products \(14\)](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) |
 [Request Sample](#) |
 [Find Similar Products](#) |
 [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [RECEPTACLE 17MM HEIGHT FH 0.8MM PITCH B-T-B CONNECTO...](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- [Free Height 0.8 mm Pitch Board-to-Board Connector \(SMT\)](#) (PDF, English)

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: [\(CAD Format & Compression Information\)](#)

- [2D Drawing](#) (DXF, Version A)
- [3D Model](#) (IGES, Version A)
- [3D Model](#) (STEP, Version A)

Additional Product Images:

- [Product Photo](#)

Related Products:

- [Tooling](#)
- [Mating Products \(14\)](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- PCB Mounting Orientation = Vertical
- Keyed = Yes
- Sealant = Without

Termination Features:

- Solder Tail Contact Plating = Tin over Nickel

Dimensions:

- [Board-to-Board Stack Height \(mm \[in\]\)](#) = 17.00 [0.669], 18.00 [0.709], 19.00 [0.748], 20.00 [0.787]
- Height = 17H

Body Features:

- [Number of Positions](#) = 200
- [Locating Post\(s\)](#) = With
- [Vacuum Cover](#) = Without
- Locating Post Length = 0.5 mm
- Number of Rows = Dual

Contact Features:

- [Contact Plating, Mating Area, Material](#) = Gold (30)
- Family Name = Free Height
- Contact Base Material = Copper Alloy

Housing Features:

- Connector Style = Receptacle
- Housing Color = Natural
- Housing Material = Liquid Crystal Polymer (LCP)
- UL Flammability Rating = UL 94V-0
- Housing Material Temperature = High

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Reflow solder capable to 245°C, Reflow solder capable to 260°C
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Features:

- [Packaging Method](#) = Tube

Other:

- Brand = AMP

Corporate Information

- [Who We Are](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

