


829068-1 Product Details

Live Product Chat US Only
 8:30am - 5pm ET, Mon - Fri

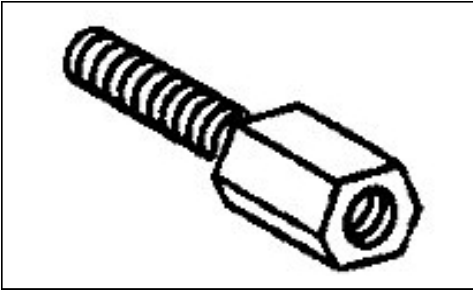

829068-1

[Active](#)

Hardware (AMPLIMITE)

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Female Screw Locks
- Tin Body Finish
- Thread Size = M3
- Thread Length = 5.00 mm
- Screwlock Style = Screwlock Only

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [screwlock female hd series](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Female Screw Locks
- [Body Finish](#) = Tin
- [Thread Size](#) = M3
- Body Material = Brass
- Comment = For Front Panel Mount.

Body Related Features:

- [Thread Length \(mm \[in\]\)](#) = 5.00 [0.197]
- Screwlock Style = Screwlock Only

Industry Standards:

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Individual

Other:

- Brand = AMP