 


[+ CABLE ASSEMBLIES](#)

LIGHTING CABLE ASSEMBLIES



TE CONNECTIVITY (TE)
NECTOR M, SEALED, 3P PANEL MT, SKT, UL
 NECTOR

2829473-1
 TE Internal Number: 2829473-1

EU RoHS Compliant
 EU ELV Compliant

Product Line **NECTOR M**

Wire Color **Black**

Cable Assembly Length **396.2 mm [15.6 in]**

Voltage Rating (VAC) **600**

Connector Type (End A) **Panel Mount Socket**
[> See All Features](#)

✓ Active

[↓](#) **PRODUCT DRAWING**
 English

[> See All Documentation](#)

North America ▾

DISTRIBUTOR	QUANTITY	DATE AS OF	
ARROW ELECTRONICS INC. 800-833-3557	10	2016/11/15	>
MOUSER ELECTRONICS (800) 346-6873	3	2016/11/16	>
FUTURE ELECTRONICS 1-800-675-1619	1	2016/11/15	>

GET SAMPLE	
SAVE TO LIST	
FIND SIMILAR PRODUCTS	

Feedback

DOCUMENTATION

FEATURES

PRODUCT COMPLIANCE

Product Drawings

[PIGTAIL BULKHEAD SOCKET STD UL CABLE](#)
 PDF
English

Catalog Pages/Data Sheets

[5-1773465-6_NECTOR_M](#)
 PDF
English

Customers Also Bought


RJ45 CONNECTORS 	RINGS & SPADES 	POWER CONTACTS 	POWER CONTACTS
-------------------------------------	--	------------------------------------	------------------------------------




VARIANT 14
COUPLER;RJ45, CAT5E,
4P, 180DEG
8-2120875-1



RING TONGUE 18-14
AWG .030 X .394 NPSTL
160701-2

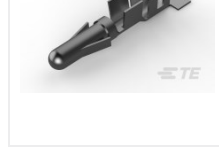

.140 DIA PIN 14-10
PTPBR
350201-1

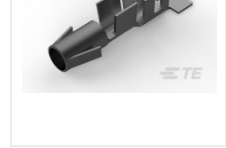

.140 DIA SOK 14-10
PTPBR
350200-1

[About TE Connectivity](#)

[For Partners](#)

[Customer Support](#)

[CALL US](#)

[LIVE CHAT](#)

[United States](#)