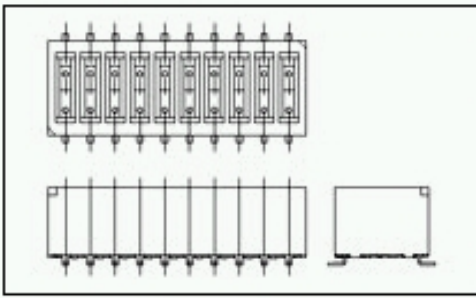


## 1825286-8 Product Details

 [Live Product Chat](#)


**1825286-8**

TE Internal Number: 1825286-8

 [Active](#)

### DIP, Rotary DIP, SIP Switches and DIP Shunts - Standard

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- DIP Switch
- PCB Mount Style = Surface Mount
- Single Pole - Single Throw Configuration (Pole-Throw)
- Actuator Style = Recessed Rocker
- Sealed

[View all Features](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

 [Add to My Part List](#)
 [Request Sample](#)
 [Find Similar Products](#)
 [Buy Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [DIP SWITCH, GDR SERIES](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- Product Type = DIP Switch
- [PCB Mount Style](#) = Surface Mount
- [Configuration \(Pole-Throw\)](#) = Single Pole - Single Throw
- [Actuator Style](#) = Recessed Rocker
- Sealed = Yes
- [Number of Switches](#) = 8

#### Termination Related Features:

- Seal Type = Tape

#### Body Related Features:

- Series = GD
- Centerline (mm [in]) = 1.27 [0.050]
- Length (mm [in]) = 21.28 [0.838]

#### Contact Related Features:

- Auto-Insertable = No
- Contact Base Material = Copper Alloy
- Contact Mating Area Plating Material = Gold

#### Housing Related Features:

- Low Profile = Yes
- Housing Color = Black
- Housing Material = PPS
- Housing Flammability Rating = UL 94V-0

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Reflow solder capable to 245°C, Reflow solder capable to 260°C
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Other:

- Brand = Alcoswitch