


## GDS08 Product Details

### Have a Question?

Chat with a Product Information Specialist

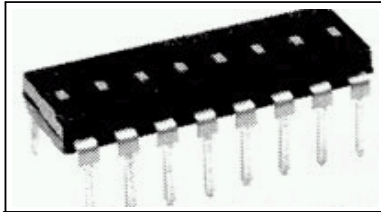

### DIP & SIP Switches - Standard

[Not EU RoHS or ELV Compliant](#) ( [Find RoHS Compliant Alternates](#) )

#### Product Highlights:

- ? Switch
- ? Switch Type = DIP
- ? PCB Mount Style = Through Hole
- ? Single Pole - Single Throw Configuration (Pole - Throw)
- ? Actuator Style = Slide

[View all Features](#)

#### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

### GDS08

(6 - 1437590 - 7)

TE Internal Number: 6 - 1437590 - 7



Superseded

[Search for Replacement Parts](#)

[Add to My Part List](#)



[Request Sample](#)



[Find Similar Products](#)



[Buy Product](#)

### Documentation & Additional Information

#### Product Drawings:

? None Available

#### Catalog Pages/Data Sheets:

? [ALCOSWITCH PRODUCTS](#) (PDF, English)

#### Product Specifications:

? None Available

#### Application Specifications:

? None Available

#### Instruction Sheets:

? None Available

#### CAD Files:

? None Available

#### Additional Information:

? [Product Line Information](#)

#### Related Products:

? [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- ? Product Type = Switch
- ? PCB Mount Style = Through Hole
- ? [Configuration \(Pole - Throw\)](#) = Single Pole - Single Throw
- ? [Actuator Style](#) = Slide
- ? Sealed = Yes
- ? [Number of Switches](#) = 8

#### Termination Related Features:

? Seal Type = Tape

#### Body Related Features:

- ? Switch Type = DIP
- ? Series = GD
- ? Centerline (mm [in]) = 2.54 [0.100]
- ? Length (mm [in]) = 20.18 [0.794]

#### Contact Related Features:

- ? Auto - Insertable = Yes
- ? Contact Base Material = Copper Alloy
- ? Contact Plating, Mating Area, Material = Gold

#### Housing Related Features:

- ? Low Profile = Yes
- ? Housing Color = Black
- ? Housing Material = PPS
- ? UL Flammability Rating = UL 94V -0

#### Industry Standards:

- ? [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- ? [Lead Free Solder Processes](#) = Wave solder capable to 240°C

#### Other:

- ? Brand = Alcoswitch

### Corporate Information

[Who We Are](#)

[Investors](#)

[News Room](#)

[Supplier Portal](#)

[Careers](#)

### Quick Links

[Check Distributor Inventory](#)

[Cross Reference](#)

[Find Documents & Drawings](#)

[Product Compliance Support Center](#)

[Site Map](#)

### Customer Support

[Email or Chat with Us](#)

[Find a Phone Number](#)

[Search Knowledge Base](#)

[Manage Your Account](#)

### Sign up for our eNewsletter

Enter your email address



### Follow Us On:



### Visit Us On:

