


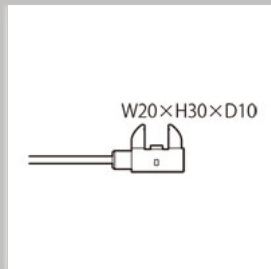

FD-F71

Part No: FD-F71



Contact Us

[Sales & Support](#)

[Send Inquiry](#)

Specifications

Item	Performance characteristics
Sensing mode	Reflective type
Fiber type	Contact type, Liquid leak detection
Fiber head length	W20 x H30 x D10 mm
With sleeve	No
Beam direction	Top-view
Fiber cable length	5 m
Allowable bending radius	R4 mm
Free-cut	Available
Semi-custom	Fiber length change, Extended protective tube
Mounting lens	Not available
Mounting protective tube	Not available
Application	Liquid leak detection / Liquid sensing
Environmental resistance : Protection	IP67
Environmental resistance : Ambient temperature MAX	60 degrees
Environmental resistance : Ambient temperature MIN	-20 degrees

Parts Inventory

Distributor	Quantity	Inventory Date
Ramco Innovations - National , United States Tel:1-800-280-6933	1	11/29/2017
Onlinecomponents.com , United States Tel:1-702-462-7300	1	11/29/2017
Master Electronics , United States Tel:1-888-473-5297	1	11/29/2017

1

Distributor	Quantity	Inventory Date
Digi-Key Electronics , United States Tel: 1-800-344-4539	2	11/29/2017

The service is owned, operated, controlled and managed by Panasonic's distributors.
For pricing, delivery and technical questions related to this service, please direct to them.
Panasonic assumes no responsibility for any dealings you may have with distributors.

Related Documents

Data Sheet
FD-F71
FD-F71
FD-F71
FD-F71
Fiber Sensor Guide Book
FX-100 Sensing Characteristics Data sheet
FX-100 Sensing range
FX-300 Sensing Characteristics Data sheet
FX-300 Sensing range
FX-311 Sensing range
FX-410 Sensing range
FX-500 Sensing Characteristics Data sheet
FX-500 Sensing range

