


Pin Assignment		
P1	BLACK	P2
1	BROWN	1
2	RED	2
3	ORANGE	3
4	YELLOW	4
5	GREEN	5
6	BLUE	6
7	PURPLE	7
8	GREY	8
9	WHITE	9
10	PINK	10
11	LIGHT GREEN	11
12	RED / BLACK	12
13	ORANGE / BLACK	13
14	YELLOW / BLACK	14
15	GREEN / BLACK	15
16	BLUE / BLACK	16
17	PURPLE / BLACK	17
18	WHITE / BLACK	18
19	RED / WHITE	19
20	ORANGE / WHITE	20
21	GREEN / WHITE	21
22	BLUE / WHITE	22
23	PURPLE / WHITE	23
24	BROWN / WHITE	24
25	DRAIN WIRE	25
SHELL		SHELL

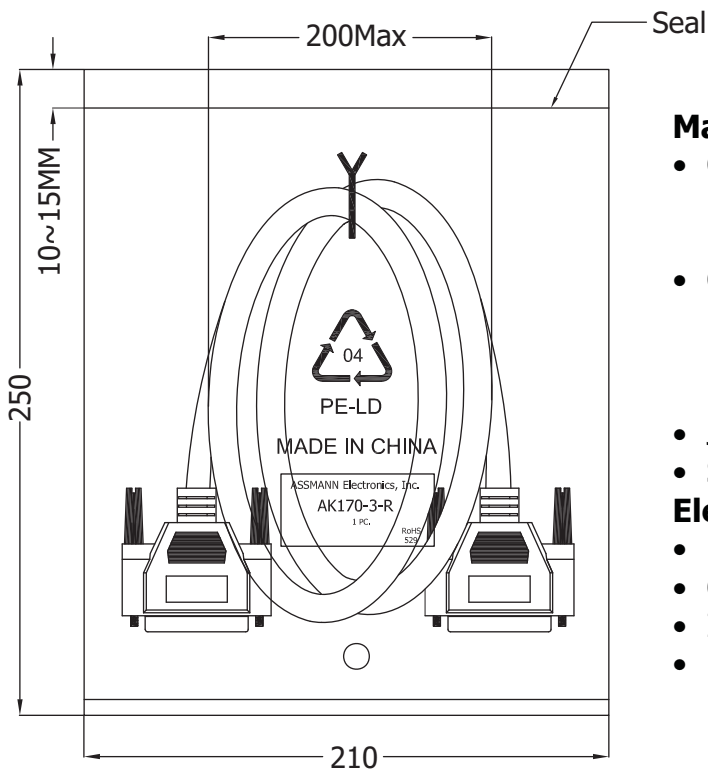

Material:

- Cable: 28AWG(7/0.12)*25C+D+AL/MY
 - OD 7.5MM
 - Jacket Beige
- Connectors: DB 25P Female Soder Type
 - Pin G/F
 - Insulator color: Blue
 - Shell Ni-Plated
- Jacket: Beige 40P PVC
- Screw: #4-40UNC Type, L=30MM, Nickel plated

Electrical:

- 100% short, open, miswire test
- Conduct resistance: 2Ω Max
- Insulation resistance: 5MΩ Min.
- Dielectric test: 300V DC

Unit: MM



ITEM NO. **AK170-3-R**

TITLE Serial Extension Cable - Shielded, 3 Meters, 25-Pin Female <=> 25-Pin Female

ASSMANN
Electronics, Inc.

1840 W. Drake Drive, Suite 101 • Tempe, AZ 85283
Toll Free: 1-877-277-6266 • Email: info@usa-assmann.com

THIS DRAWING IS UNPUBLISHED
©Copyright 2011 by Assmann Electronic Components
All International Rights Reserved