
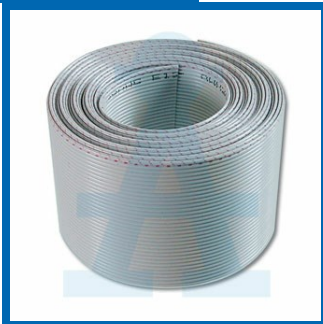


Product 2/32

[Previous](#)

[Product Listing](#)

[Next](#)

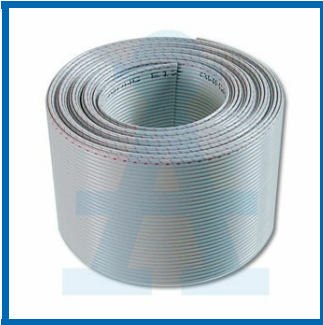

[larger image](#)  
[larger image](#)

**Grey Ribbon Cable, 28AWG 1.0MM Pitch, 5 Conductors, 300Ft**

**Part Number:** **AWG28-05/G-1/300**

**More Information:**

[>> Contact AWSW](#)



[Product Specification sheet](#)

**Product Information:**

Previously known as: **AWG28-05/G-1/300-R**

**Grey Ribbon Cable, 28AWG, 1.0MM Pitch, 5 Conductors, 300 Feet, 13" Reel**

**Conductor:**

- AWG: 28AWG
- Material: TC
- Size: 7/∅×0.125±0.008MM



**Jacket:**

- Min. Avg. Thick: 0.26MM
- Material: 105°C 45P UL-PVC
- Color: Grey (Half Atomizer)
- OD: 0.90MM±0.10\*10.0MM±0.30MM
- Tensile Strength: before aging: 1,500PSI
- Tensile Strength: after aging: 70% Min.(136°C\*168H)
- Elongating - before aging: 100% Min.
- Elongating - after aging: 65% Min. (136°C\*168H)
- Deformation Test: 50% Max. (121°C\*1H)
- Cold Bent Test: -10°C\*4H No Cracking
- Horizontal Flame Test: VW-1

**Electrical:**

- Rating: Temp 105°C
- Voltage: 300V
- Dielectric Strength: 2.0KV 60Hz Minute
- Conductor Resistance: at 20°C
- Insulation Resistance: 100M/M Min. @500V DC
- Max: 237.25Ω/KM
- UL Certified
- UL Style: 2651-VW-1


**Have you seen ...**



**Assmann WSW links**

- [Assmann WSW components](#)
- [Assmann Germany](#)
- [Assmann Custom cables](#)
- [RoHS Compliance](#)
- [Product Change Notification](#)
- [End Of Life Notification](#)
- [Conflict Free Minerals Declaration](#)
- [Assmann mail](#)
- [Advanced Search](#)

## Recently Viewed

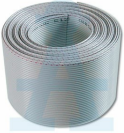

Grey Ribbon Cable, 28AWG 1.0MM Pitch, 5 Conductors, 300Ft

[Shipping & Returns](#) | [Privacy Notice](#) | [Contact AWSW](#) | [Site Map](#)



Your IP Address is: 35.164.3.180



Assmann WSW components, Inc.  
1840 W. Drake Drive, Suite 101, Tempe, AZ. 85283  
Phone: 877-277-6266 • [www.Assmann.us](http://www.Assmann.us)

Copyright © 2006-2018 Assmann WSW components, Inc.. All rights reserved.