


### EI57-20.0VA TRANSFORMER AH600 SERIES

#### FEATURES,

- UL5015-1,-3 Approved:UL File No.E177998
- Class B Insulation System
- Split bobbin Design
- Dielectric Strength 2500Vrms
- Optional Single 115V or Dual 115/230V Primaries at 50/60Hz
- Standard Dual Secondaries
- 5 Standard Sizes for a Variety of Power Application

#### OUTLINE DIMENSIONS

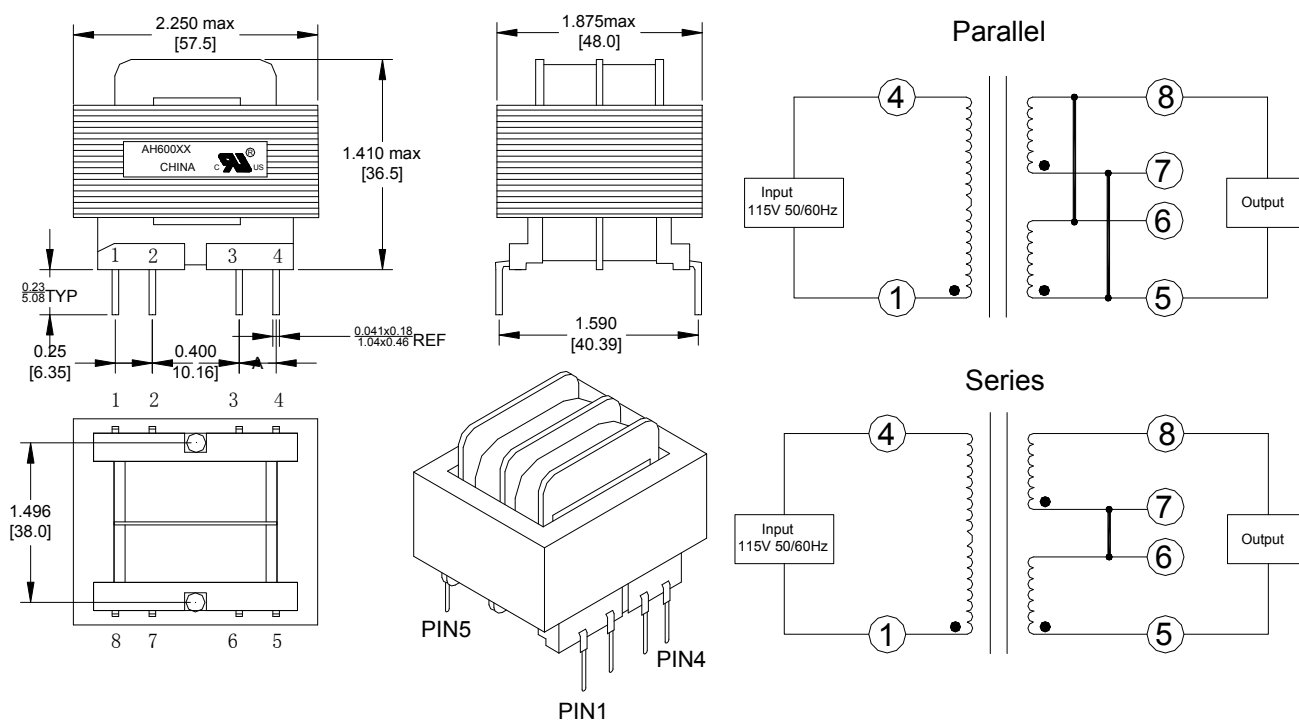

#### ELECTRONIC SPECIFICATIONS

Part NO	Input Voltage (V)	Series		Parallel		Rated Power (VA)	Certificate	
		Voltage (Vac)	Current (mA)	Voltage (Vac)	Current (mA)		UL	CE
AH60010	115V	10	2000	5	4000	20.0VA	•	
AH60012	115V	12.6	1600	6.3	3200	20.0VA	•	
AH60016	115V	16	1250	8	2500	20.0VA	•	
AH60020	115V	20	1000	10	2000	20.0VA	•	
AH60024	115V	24	800	12	1600	20.0VA	•	
AH60028	115V	28	700	14	1400	20.0VA	•	
AH60036	115V	36	550	18	1100	20.0VA	•	
AH60048	115V	48	400	24	800	20.0VA	•	
AH60056	115V	56	350	28	700	20.0VA	•	
AH600120	115V	120	160	60	320	20.0VA	•	