


# Product Support

# Part & Model Reference

- Model & Part Search
- Videos
- Technical Literature
- Software
- CAD Files
- Catalogs
- Brochures
- Product Warranty
- Worldwide Locations
- SISTEMA Library

## MBCC-412 P/N 25226

Mini-style Quick Disconnect Cable  
 4 Pin Female Pin-out Straight  
 Connector  
 4 m (12 ft) in Length  
 Nylon coupling nut

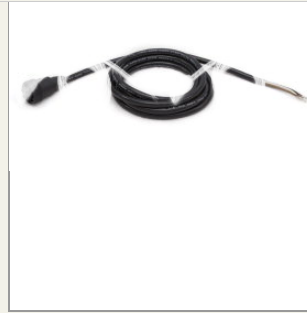

**BUY ONLINE \$45 (USD)**

**Contact a Banner Engineer  
 About Your Application**



- Specifications**
- Diagrams
- Family Overview

### Specifications

Primary Connector Type	MIN
Coupling Method	7/8"-16
Number of Pins	4
Gender	Female
Orientation	Straight
Length (m)	3.66
Connector Body Material/Color	PUR Black
Number of Connectors	1
Number of Wires	4
Secondary Connector Type (or Branch 1 connector)	Flying Leads
Gauge (AWG)	18
Cable Jacket Material	PVC
Cable Jacket Color	Black
Outside Cable Diameter (mm)	7
Shield	No Shield
AC Voltage/current	300V/9A
DC Voltage/current	300V/9A
Minimum Temp. (Celsius)	-40
Maximum Temp. (Celsius)	80
IEC IP67	Y
IEC IP68	N
IEC IP69K	N

**Banner Insider eNewsletter**  
 Helpful application information, new product updates, answers to frequently asked questions, and more.  
[Subscribe Now >](#)

**Banner makes your job easier**

- » Rapid customization - in days, not weeks
- » Strongest application engineers in the industry
- » Inventory and service worldwide

**WORLDWIDE DISTRIBUTORS**  
 Banner has more than 3,000 distributors—ready to help you. Enter your U.S. city or zip.  
   
 ▶ Find international distributors