






Back

Selected Cable: 17002A				
End View	Plug	Cord	Connector	End View
				
5-15P	290B	SVT	386	C13

Cord View

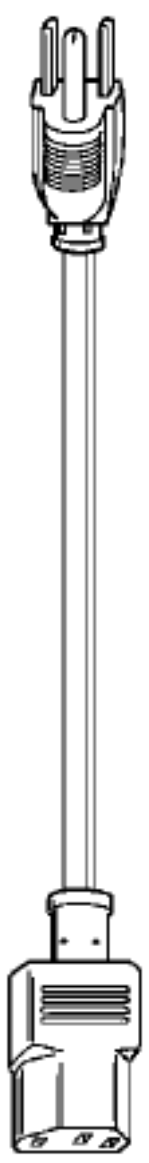

Part Number	17002A
Category	3 conductor plastic detachable
Shielding	unshielded
Jacket Color	Black,
Length Feet	1'6"
Length Meters	0.46
Temperature Rating	60 C°C
Packaging Units Per Carton	B-25, S25
Color Coding	North America
AWG Stranding	18 (41x34)
Nominal OD Inch	0.246
Nominal OD millimeter	6.25
Rating	1250 Watts 10A-125V
Notes	

Approvals



Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

