


Back

Selected Cable: 17254

End View	Plug	Cord	Connector	End View
NONE	NONE	SVT	386	C13

Cord View

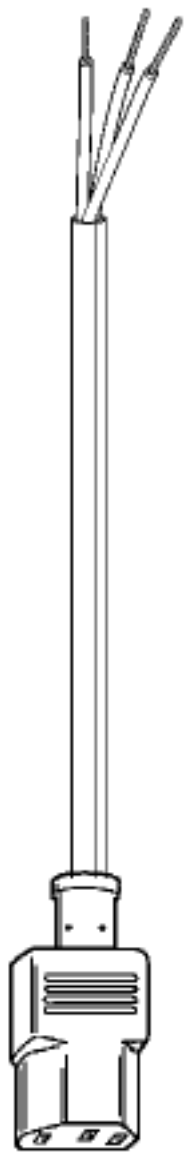

Part Number	17254
NSN	6150-01-047-5349
Category	3 conductor plastic original equipment cords
Shielding	unshielded
Jacket Color	black
Length Feet	7'6
Length Meters	2.29
Temperature Rating	60 C°C
Packaging Units Per Carton	H-100,H25
Color Coding	International
AWG Stranding	18 (41x34)
Nominal OD Inch	0.246
Nominal OD millimeter	6.25
Rating	1250 Watt 10A-125V (*)
Notes	(*)Dual rated at 10A-250V.

Approvals



Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

