


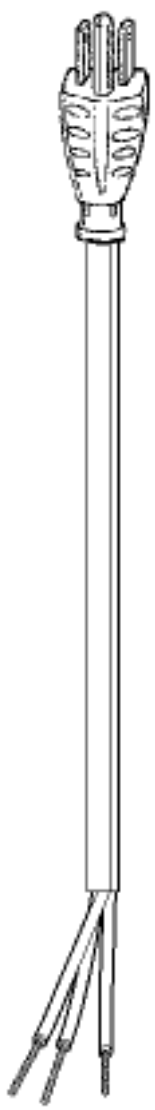


**Back**

**Selected Cable: 17419**

End View	Plug	Cord	Connector	End View
				
5-15P	185	SJ	3"STRIP	NONE

**Cord View**



<b>Part Number</b>	<b>17419</b>
<b>NSN</b>	5995-01-073-7428, 6150-00-071-1180, 6150-00-064-5886
<b>Category</b>	2 and 3 conductor rubber original equipment cords
<b>Shielding</b>	unshielded
<b>Jacket Color</b>	black
<b>Length Feet</b>	9'
<b>Length Meters</b>	2.74
<b>Temperature Rating</b>	60 C°
<b>Packaging Units Per Carton</b>	B-25,S-15
<b>Color Coding</b>	North America
<b>AWG Stranding</b>	16 (26x30)
<b>Nominal OD Inch</b>	0.34
<b>Nominal OD millimeter</b>	8.64
<b>Rating</b>	1625 Watts 13A-125V

**Approvals**

**Notes**

See 17422 for 12ft version. See 40328 for 8ft version w/ cord grip plug.



Qty:

**Back**

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268  
800-246-CORD. [info@volexpowercords.com](mailto:info@volexpowercords.com)

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

