






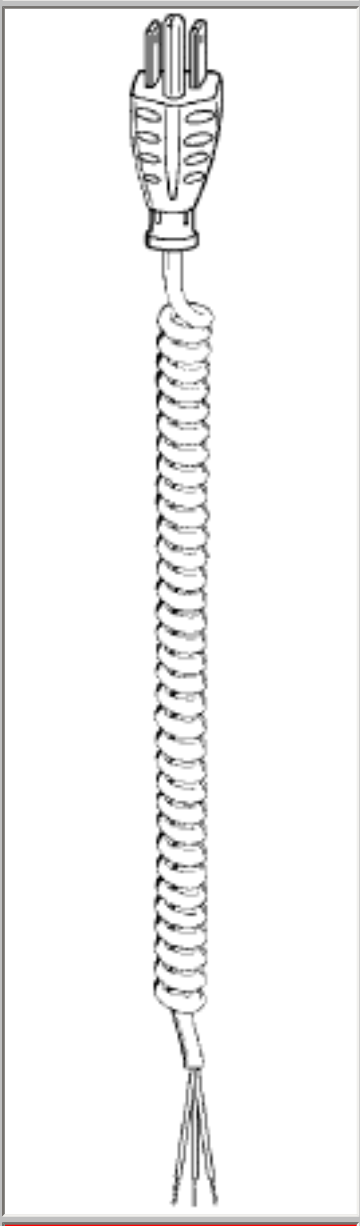
[Back](#)

Selected Cable: 17447

End View	Plug	Cord	Connector	End View
				
5-15P	290B	SJO	3"STRIP	NONE

Part Number	17447
Category	3 conductor rubber original equipment cords
Subcategory	RETRACTILE
Shielding	unshielded
Jacket Color	black
Length Feet	1' (RETRACTED)
Length Meters	0.3
Temperature Rating	60 C°C
Packaging Units Per Carton	S-25
Color Coding	North America
AWG Stranding	18 (41x34)
Nominal OD Inch	1.33
Nominal OD millimeter	9.14
Rating	1250 Watts 10A-125V

Cord View



Approvals

Notes

Practical length: 6'(1.83m) Retracted length: 12". See 17448 for 16 gauge version.



Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

