




[Back](#)

| Selected Cable: 17462 | | | | |
|-----------------------|------|------|-----------|----------|
| End View | Plug | Cord | Connector | End View |
| | | | | |
| 5-15P | 745 | SJT | 108 | 5-15R |

| | |
|-----------------------------------|---|
| Part Number | 17462 |
| NSN | 6150-01-035-8901 |
| Category | extension cords rubber and plastic |
| Subcategory | ADD A LINE |
| Jacket Color | black |
| Length Feet | 8' |
| Length Meters | 2.44 |
| Temperature Rating | 60 C° |
| Packaging Units Per Carton | S-10 |
| Color Coding | North America |
| AWG Stranding | 16 (26x30) |
| Nominal OD Inch | 0.34 |
| Nominal OD millimeter | 8.64 |
| Rating | 1625 Watts 13A-125V |
| Notes | Restricted use only. Add-a-line plug. See 17463 for 15ft version. |

Cord View

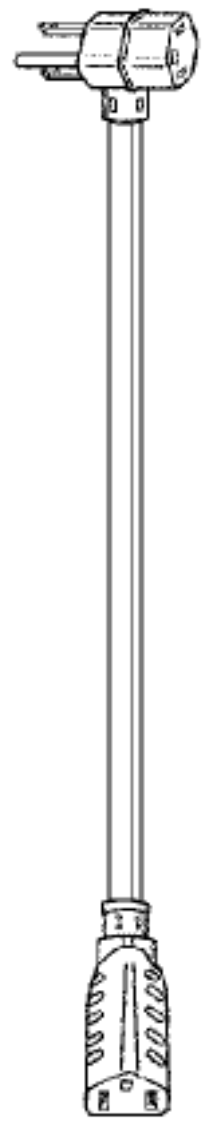

Approvals



Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

