


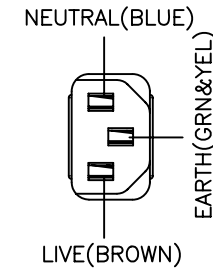
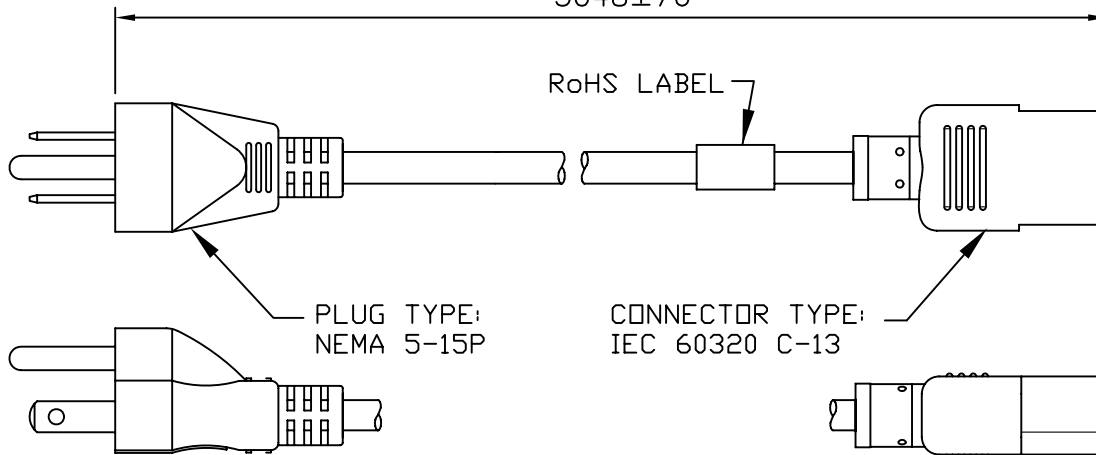
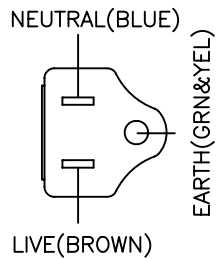
VOLEX

GROUP

Standard Cord Details: 17505 10 B1




Specifications	
Certifications	
Part Number	17505 10 B1
Connector Type	C13
Plug Type	5-15P
Category	Plastic
Application	Detachable
Plug Catalog No.	PS204
Connector Catalog No.	386A
Cable	SJT AWG 14x3
Jacket Color	black
Length in Feet	9'10
Length in Meters	3
Temperature Rating	60 C
Packaging Units Per Carton	50
Color Coding	International
Nominal OD in Inches	0.38
Nominal OD in Millimeters	9.65



VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

PACKAGING: FOLD & TIE

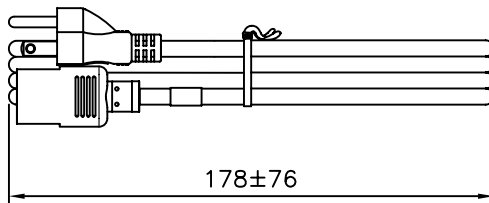

NOTES:

- 1) CORDAGE: 14/3 SJT, 60°C, BLACK
- 2) APPROVALS:
- 3) RATING: 15 AMP/125 VOLTS
- 4) CORDAGE O.D. : .380 (REF.)
- 5) PACKAGING: 50 PIECES/CARTON
- 6) ALL DIMENSIONS IN MILLIMETERS.

3	CHANGED TO REPRESENT ASIAN MANUFACTURED CORDS	5/7/08
2	FORMAT UPDATE	08/19/04
1	C.U.D - NEW RELEASE	06/09/04
REV	DESCRIPTION	DATE



FORM IN71-07 REV.A

- Indianapolis, IN
- Conover, N.C.
- Freemont, CA
- Aguascalientes, MX
- Tijuana, Mexico
- Hermosillo, MX
- Clinton, AR
- Kanata, Canada

Proprietary Notice:

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

MATERIAL:
PLUG: PVC, BLACK
JACKET: PVC, BLACK

FINISH:
JACKET: SMOOTH

SCALE:
NOT TO SCALE

ECD:
N/A

ITEM DESCRIPTION
CORDSET - NORTH AMERICAN
DETACHABLE POWER SUPPLY CORD (9')

TOLERANCE UNLESS OTHERWISE SPECIFIED
.XXX ± .005
.XX ± .02
.X ± .03
FRACT. ± 1/32
ANGULAR ± 1/2°

APPROVED CR	DRAWN BY ARK	DATE: 06/09/04
----------------	-----------------	-------------------

PART NO.
17505 10 B1