

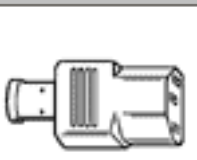

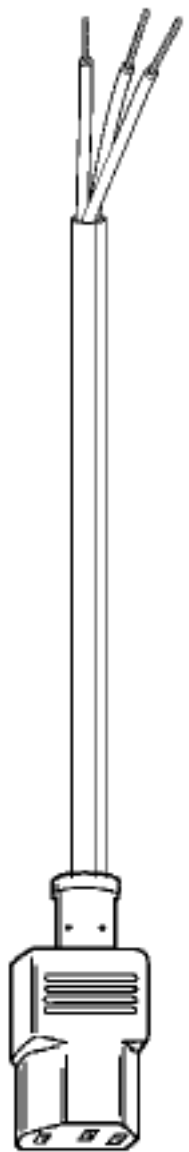


Back

| Selected Cable: 17521 | | | | |
|-----------------------|---|---|---|---|
| End View | Plug | Cord | Connector | End View |
| |  |  |  |  |
| NONE | 3"STRIP | SJT | 386E | C13 |

Cord View



| | |
|-----------------------------------|--|
| Part Number | 17521 |
| Category | 3 conductor plastic original equipment cords |
| Shielding | unshielded |
| Jacket Color | black |
| Length Feet | 9'10" |
| Length Meters | 3 |
| Temperature Rating | 60 C°C |
| Packaging Units Per Carton | H-50,H-25 |
| Color Coding | International |
| AWG Stranding | 16 (26x30) |
| Nominal OD Inch | 0.34 |
| Nominal OD millimeter | 8.64 |
| Rating | 1625 Watts 13A-125V (*) |
| Notes | See 17520 for 6'7" version. See 17519 for 18 gauge version. See 17621 for shielded version. 17521 is dual rated at 13A-250V. |

Approvals



Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

