


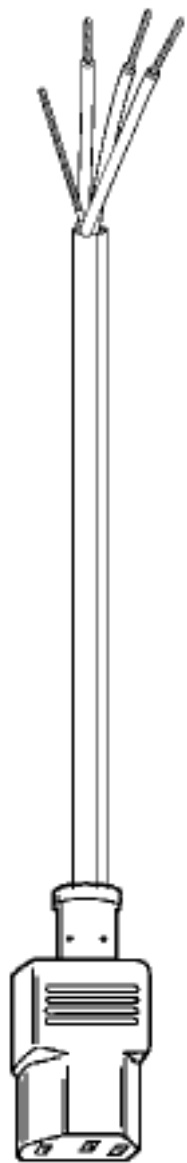




Back

Selected Cable: 17619				
End View	Plug	Cord	Connector	End View
				
NONE	NONE	SJT BELDFOIL SHIELDED	386A	C13

Cord View



Part Number	17619
NSN	6150-01-255-3985
Category	3 conductor plastic original equipment cords
Shielding	Beldfoil Shielded
Jacket Color	black
Length Feet	9'10"
Length Meters	3
Temperature Rating	60 C°C
Packaging Units Per Carton	H-100,H-25
Color Coding	International
AWG Stranding	18 (41x34)
Nominal OD Inch	0.34
Nominal OD millimeter	8.63
Rating	1250 Watts 10A-125V (*)

Approvals

Notes

(*)Dual rated at 10A-250V. See 17621 for 16 gauge version. See 17519 for unshielded version.



Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

