






Back

Selected Cable: 17742				
End View	Plug	Cord	Connector	End View
				
5-15P	290B	SVT BELDFOIL SHIELDED	386A	C13

Cord View

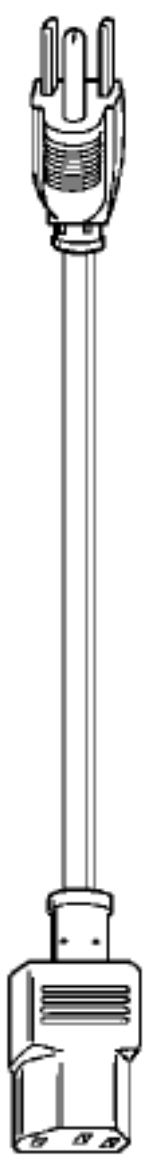

Part Number	17742
NSN	6150-01-134-9121
Category	3 conductor plastic detachable
Shielding	Beldfoil Shielded
Jacket Color	black
Length Feet	6'7"
Length Meters	2
Temperature Rating	60 C°C
Packaging Units Per Carton	H-100,H-25
Color Coding	International
AWG Stranding	18 (41x34)
Nominal OD Inch	0.253
Nominal OD millimeter	6.43
Rating	1250 Watts 10A-125V

Approvals

Notes

See 17743 for 9'10" version. See 17725 for 105C version. See 17660 for foil & braid shielded version.



Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

