


ISSUE REF. NO.	DESCRIPTION	DATE
002	CHANGE TITLE FM. 'UNIVERSAL JUMPER CORDSET (PB FR)' TO 'EUROPEAN+CHINESE+NORTH-AMERICAN JUMPER CORDSET (PB FR)' ON PAGE 1 & 2.	14/11/12
003	CHANGE MARKING DETAILS OF PLUG & CONNECTOR AS SHOWN ON PAGE 1.	14/11/12
003	CHANGE FORMAT FM. 'TWO PAGE SPEC' TO 'ONE PAGE SPEC'.	05/12/12

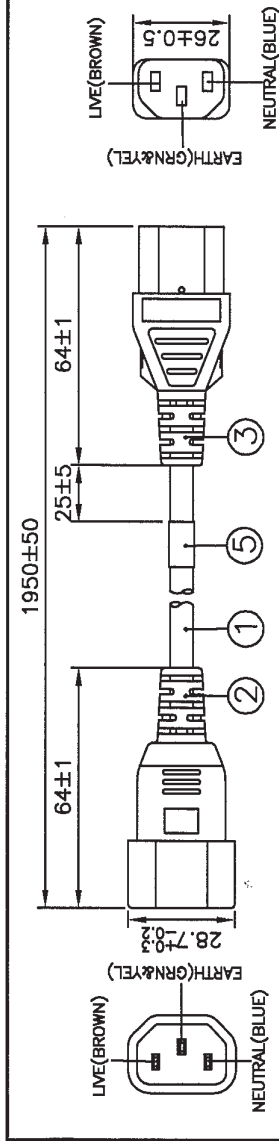

NOTE :

- ALL DIMENSIONS IN mm.
- THIS PART CAN BE MANUFACTURED AT ANY LOCATION WHICH HAS SAFETY APPROVAL.
- RoHS COMPLIANT.
- LABEL DETAILS : REFER TO LABEL DRAWING NO. : VL-0356.
- THE WITHDRAWAL FORCE OF CONNECTOR V1625 IS ABLE TO MEET 30N to 45N WHEN MATING WITH THE APPLIANCE INLET WITH NOMINAL DIMENSIONS.
- CARTON BOX MUST HAVE A LABEL/STAMP SAYING : " THIS PACKAGE CONTAINS CORDS HAVING GROUNDING CONDUCTOR WITH GREEN/YELLOW COLOUR INSULATOR, GROUNDED CONDUCTOR WITH BLUE COLOUR INSULATOR AND LIVE CONDUCTOR WITH BROWN COLOUR INSULATOR " .
- PACKAGING QTY. : 100 PCS PER CARTON.

5	PRINTED LABEL	VL-0356	1
4	6" PE TIE BLK	6310056	1
3	MOLDED CONNECTOR V1625 (10A 250V)	4100115	1
2	MOLDED PLUG VAC14S (10A 250V)	4100115	1
1	RW 3X0.75 BLK LF (EURO+UL/CSA+CCC)	1220031	1

S/N	DESCRIPTION	ITEM NUMBER	QTY
TITLE : EUROPEAN+CHINESE+NORTH-AMERICAN JUMPER CORDSET (PB FR)			
CUSTOMER : VNA/VOLEX INC			
CUSTOMER PART NUMBER : 2173H			
Reference Number : 113103/7 (HG11-243-12)			
SALES : OA <i>Ben</i> ENGRG : <i>Wid</i> CHECKED BY : <i>Hui</i> DRAWN BY : LI MIN			
Date : 7/12/12 Date : 6/12/12 Date : 06/12/12 Date : 05/12/12			
APPROVED BY : SIGNATURE : APPROVED DATE :			
CUSTOMER APPROVED :			
APPROVED BY : SIGNATURE : APPROVED DATE :			

PLUG TYPE	IEC 60320-2-2, EN 60320-2-2 - STANDARD SHEET E. GBT7465.2
CONNECTOR TYPE	C13
CABLE OUTER DIAMETER	6.0 ~ 7.6
TEMPERATURE	75°C
CORDSET RATING(AMP/VOLTAGE)	10A/250V

APPROVED SOURCE FOR CABLE

1. BAO HING(SHENZHEN).

APPROVAL MARKING TABLE:

Confidential property of Volex. Information contained herein shall not be disclosed to any other person without written permission by an authorized official of Volex Asia.

Volex (Asia) Pte Ltd