



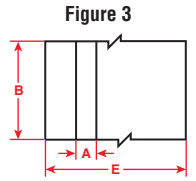

Thermal Transfer Labels

Label Index By Size

Label Index By Size (Continued)

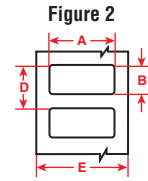

Part Number	Labels Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horiz. Repeat Inch (mm) C	Vert. Repeat Inch (mm) D	Web Width Inch (mm) E	Suggested Ribbon	Diagram
4.000" Label Width (Continued)											
THT-55-449-1	1,000	Polypropylene	White	1	4.000 (101.6)	2.000 (50.8)	-	2.125 (54.0)	4.200 (106.7)	R6207	Fig. 2
THT-55-480-1	1,000	Polyester	Silver	1	4.000 (101.6)	2.000 (50.8)	-	2.125 (54.0)	4.200 (106.7)	R6007	Fig. 2
THT-55-483-1	1,000	Polyester	White	1	4.000 (101.6)	2.000 (50.8)	-	2.125 (54.0)	4.200 (106.7)	R6007	Fig. 2
THT-55-484-1	1,000	Polyester	White	1	4.000 (101.6)	2.000 (50.8)	-	2.125 (54.0)	4.200 (106.7)	R6007	Fig. 2
THT-55-489-1	1,000	Polyester	White	1	4.000 (101.6)	2.000 (50.8)	-	2.125 (54.0)	4.200 (106.7)	R4307	Fig. 2
XHT-55-8423-3	3,000	Polyester	White	1	4.000 (101.6)	2.000 (50.8)	-	2.125 (54.0)	4.200 (106.7)	R6207	Fig. 2
THT-76-422-1	1,000	Polyester	White	1	4.000 (101.6)	3.000 (76.2)	-	3.125 (79.4)	4.200 (106.7)	R6007	Fig. 2
THT-76-425-1	1,000	Polypropylene	White	1	4.000 (101.6)	3.000 (76.2)	-	3.125 (79.4)	4.200 (106.7)	R4307	Fig. 2
THT-76-449-1	1,000	Polypropylene	White	1	4.000 (101.6)	3.000 (76.2)	-	3.125 (79.4)	4.200 (106.7)	R6207	Fig. 2
THT-76-483-1	1,000	Polyester	White	1	4.000 (101.6)	3.000 (76.2)	-	3.125 (79.4)	4.200 (106.7)	R6007	Fig. 2
THT-76-489-1	1,000	Polyester	White	1	4.000 (101.6)	3.000 (76.2)	-	3.125 (79.4)	4.200 (106.7)	R4307	Fig. 2
XHT-76-8425-1	1,000	Polypropylene	White	1	4.000 (101.6)	3.000 (76.2)	-	3.125 (79.4)	4.200 (106.7)	R6207	Fig. 2
THT-77-402-1.4	1,400	Paper	White	1	4.000 (101.6)	4.000 (101.6)	-	4.125 (104.8)	4.125 (104.8)	R6107	Fig. 2
THT-161-423-1	1,000	Polyester	White	1	4.000 (101.6)	4.000 (101.6)	-	4.125 (104.8)	4.200 (106.7)	R6007	Fig. 2
THT-161-483-1	1,000	Polyester	White	1	4.000 (101.6)	4.000 (101.6)	-	4.125 (104.8)	4.200 (106.7)	R6007	Fig. 2
THT-161-486-1	1,000	Metallized Polyester	Silver	1	4.000 (101.6)	4.000 (101.6)	-	4.125 (104.8)	4.200 (106.7)	R4307	Fig. 2
THT-25-402-1	1,000	Paper	White	1	4.000 (101.6)	6.000 (152.4)	-	6.125 (155.6)	4.200 (106.7)	R6107	Fig. 2
THT-25-408-1	1,000	Paper	White	1	4.000 (101.6)	6.000 (152.4)	-	6.125 (155.6)	4.200 (106.7)	R6107	Fig. 2
THT-25-424-1	1,000	Paper	White	1	4.000 (101.6)	6.000 (152.4)	-	6.125 (155.6)	4.200 (106.7)	R4307	Fig. 2
THT-78-402-0.9	900	Paper	White	1	4.000 (101.6)	6.500 (165.1)	-	6.625 (168.3)	4.125 (104.8)	R6107	Fig. 2
THT-78-408-1	1,000	Paper	White	1	4.000 (101.6)	6.500 (165.1)	-	6.625 (168.3)	4.200 (106.7)	R6107	Fig. 2
THT-107-413	1 Roll	Polyester	Silver	1	4.000 (101.6)	300 ft (91.4 m)	-	300 ft (91.4 m)	4.200 (106.7)	R6007	Fig. 3
THT-107-423	1 Roll	Polyester	White	1	4.000 (101.6)	300 ft (91.4 m)	-	300 ft (91.4 m)	4.200 (106.7)	R6007	Fig. 3
THT-107-428	1 Roll	Metallized Polyester	Silver	1	4.000 (101.6)	300 ft (91.4 m)	-	300 ft (91.4 m)	4.200 (106.7)	R4307	Fig. 3
THT-107-439	1 Roll	Vinyl	White	1	4.000 (101.6)	300 ft (91.4 m)	-	300 ft (91.4 m)	4.200 (106.7)	R6007	Fig. 3
THT-107-480	1 Roll	Polyester	Silver	1	4.000 (101.6)	300 ft (91.4 m)	-	300 ft (91.4 m)	4.200 (106.7)	R6007	Fig. 3
THT-107-483	1 Roll	Polyester	White	1	4.000 (101.6)	300 ft (91.4 m)	-	300 ft (91.4 m)	4.200 (106.7)	R6007	Fig. 3
THT-107-486	1 Roll	Metallized Polyester	Silver	1	4.000 (101.6)	300 ft (91.4 m)	-	300 ft (91.4 m)	4.200 (106.7)	R4307	Fig. 3

Note: Labels in chart are sorted in order by width, height, vertical repeat, die number and material number.