


Label Index by Size

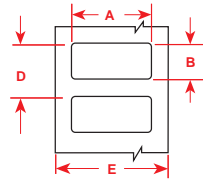

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
2.000" Label Width										
THT-15-351-2.5	2,500	Tamper-Resistant Vinyl	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6200
THT-15-423-2.5	2,500	Polyester	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6000
THT-48-423-10	10,000	Polyester	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-15-426-2.5	2,500	Polyimide	Amber	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R4302
THT-48-426-10	10,000	Polyimide	Amber	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R4302
THT-15-457-2.5	2,500	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6000
THT-48-457-10	10,000	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-15-473-2.5	2,500	Polyester	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6000
THT-48-473-10	10,000	Polyester	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-15-477-2.5	2,500	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6000
THT-48-477-10	10,000	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-48-478-10	10,000	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-48-479-10	10,000	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-15-487-2.5	2,500	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6000
THT-48-487-10	10,000	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-15-488-2.5	2,500	Polyester	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R4302
THT-48-495-10	10,000	PEN	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-48-497-10	10,000	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-15-497-2.5	2,500	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6000
THT-151-499-3	3,000	Nylon Cloth	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R4302
THT-79-423-10	10,000	Polyester	White	1	2.000 (50.80)	0.400 (10.16)	—	0.500 (12.70)	2.200 (55.88)	R6000
THT-53-351-3	3,000	Tamper-Resistant Vinyl	White	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R6200
THT-53-352-3	3,000	Tamper-Resistant Vinyl	Silver	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R6000
THT-53-423-3	3,000	Polyester	White	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R6000
THT-53-424-3	3,000	Paper	White	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R4302
THT-53-428-3	3,000	Metallized Polyester	Silver	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R4302
THT-53-438-3	3,000	Tamper-Evident Polyester	Silver	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R4302
THT-53-486-3	3,000	Metallized Polyester	Silver	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R4302
THT-53-7546-3	3,000	Tamper-Evident Polyester	White	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R6000
THT-53-7576-3	3,000	Tamper-Evident Polyester	Silver	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R6000
THT-17-351-3	3,000	Tamper-Resistant Vinyl	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6200
THT-17-352-3	3,000	Tamper-Resistant Vinyl	Silver	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6000
THT-17-354-3	3,000	Polyester/Paper	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6200
THT-17-358-3	3,000	Tamper-Resistant Acetate	Clear	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6200
THT-17-359-3	3,000	Tamper-Resistant Acetate	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6200
THT-17-7566-3	3,000	Tamper-Evident Polyester	Clear	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6200
XHT-17-8425-5	5,000	Polypropylene	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6000
THT-17-402-5.2	5,200	Paper	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6100
THT-17-408-3	3,000	Paper	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6100
THT-17-422-3	3,000	Polyester	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6000
THT-17-423-3	3,000	Polyester	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6000
THT-17-424-3	3,000	Paper	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302
THT-137-427-AW-3*	3,000	Vinyl	White/ Transparent	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302
THT-17-428-3	3,000	Metallized Polyester	Silver	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302
THT-17-430-3	3,000	Polyester	Clear	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6000
THT-17-434-3	3,000	Metallized Polyester	Silver	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6000
THT-17-438-3	3,000	Tamper-Evident Polyester	Silver	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302
THT-17-449-3	3,000	Polypropylene	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6200
THT-17-483-3	3,000	Polyester	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6000
THT-17-486-3	3,000	Metallized Polyester	Silver	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302
THT-17-488-3	3,000	Polyester	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302

Note: Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).

LABEL INDEX BY SIZE THERMAL TRANSFER LABELS