



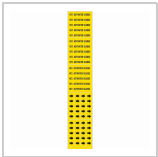

Pipe and Valve Marking / Pipe Markers / Pipe Markers for Other Liquids /
RET. ACTIVATED SLUDGE Pipe Marker

RET. ACTIVATED SLUDGE Pipe Marker

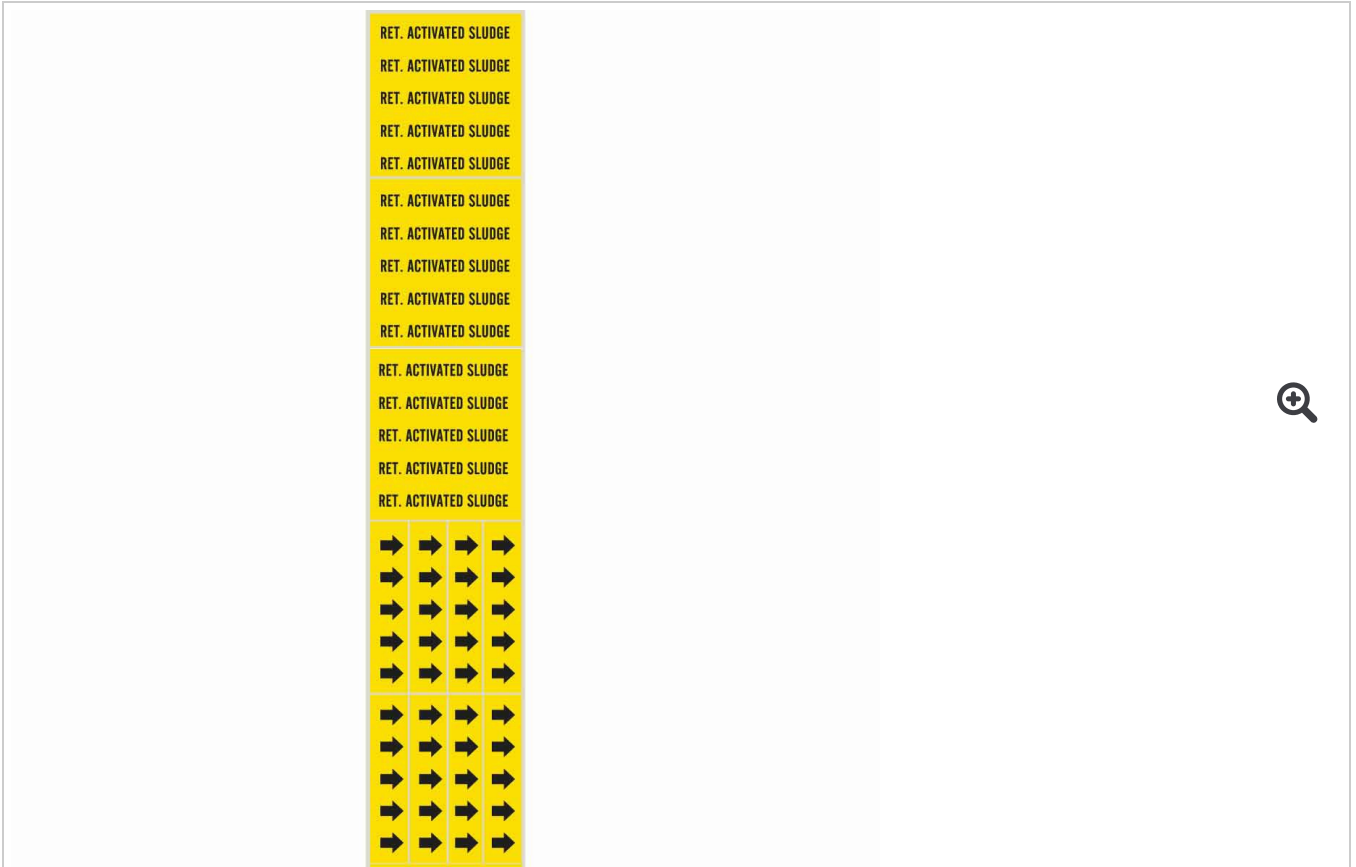

Product Highlights:

Material:

Vinyl

Text Legend:

RET. ACTIVATED SLUDGE

Pipe Marker Mounting Style:

Self-Adhesive

Color:

Black on Yellow

Choose your options: [Reset Options](#)

1 Overall Size

FITS PIPES 0.75IN DIA. OR SMALLER ▾

Part Number:

7245-3C



[View All Options](#)

ADD TO CART

+

-



Add To Favorites

Customers Also Bought



SLUDGE


SLUDGE Pipe Marker

from **\$1.89**

DIGESTED SLUDGE

DIGESTED SLUDGE Pipe Marker

from **\$1.89**

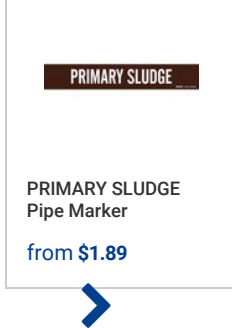

Overview

Self-sticking pipe markers from Brady® simplify installation with their factory-applied industrial-grade adhesives: simply peel off the backing and press the marker in place.

- Banding each end of a pipe marker with directional flow arrow tape is recommended
- Style 3C pipe markers measure 2-1/4 in. x 2-3/4 in. and fit pipe diameters less than 3/4 in.
- High gloss, durable, flexible vinyl with a permanent cold temperature pressure sensitive acrylic adhesive
- Good chemical, oil and water resistance

Specifications

Key Characteristics		349
	Product Number	81645
	UPC	754473816452
	UOM	Card of 3 Each
	Quantity per Card or Sheet	3
	Brand Name	Brady®
		United States of America
		4911.99.8000
		EAR99

Dimensions	Sign Size (H x W)	2.25" x 2.75"
	Dimensions	2.25 in H x 2.75 in W
	Height	2.25 in
	Width	2.75 in
	Thickness	0.004 in
	Size	3C

--	--	--

Material Characteristics		B-946 (View Technical Data Sheet)
		Vinyl
	Label Properties	Aggressive Adhesive, Permanent Adhesive, Standard High Quality
	Adhesive Type	Permanent Acrylic
	Finish	Gloss
	Color	Black on Yellow
	Resistance Properties	Abrasion-Resistant, Chemical-Resistant
	Indoor or Outdoor Use	Outdoor Use
	Service Temperature Range °F	-40 °F - 180 °F
	Minimum Service Temperature °F	-40 °F
	Maximum Service Temperature °F	180 °F
	Minimum Application Temperature °F	0 °F
		Non-Reflective
	Compatible Surface Types	General

Product Features		Pipe and Valve Marking
		8 to 10 Years
		Self-Adhesive

Compatibility	Overall Size	Fits Pipes 0.75in Dia. or smaller
	Maximum Outside Pipe Diameter	0.75 in

Preprinted Information	Text Legend	RET. ACTIVATED SLUDGE
	Pre-Printed Areas on Label	Pipe Contents
	Character Height	0.5 in
	Language	English

Compliance		55121737
-------------------	--	----------



You May Also Like



B30 Series Continuous Indoor Outdoor Vinyl Labels

Multiple Options Available from **\$72.39**



BMP21-PLUS Printer Kit

BMP21-PLUS-KIT1
\$195.00



HandiMark Indoor Outdoor Vinyl Labels

Multiple Options Available from **\$68.09**



BMP71 BMP61 M611 TLS 2200 Self-Laminating Vinyl Wire and Cable Labels

Multiple Options Available from **\$20.09**



Support

— LITERATURE

[Pipe and Valve Identification Brochure](#)

[Pipe Marking Guideline for Color and Size Identification](#)

Recently Viewed



DANGER High Voltage Sign

Multiple Options Available from **\$9.19**

Corporate

- [About](#)
- [Careers](#)
- [Investors](#)
- [Do Not Sell My Personal Info](#)
- [Privacy Policy](#)
- [Terms and Conditions](#)
- [ISO Certificates](#)

Other Brady Sites

- [Distributor Portal](#)
- [International Sites](#)
- [Brand Protection Solutions](#)

Help

- [Contact Us](#)
- [Customer & Technical Support](#)
- [Resource Center](#)
- [Searchable Support Articles](#)
- [Certificate Request](#)
- [Website Feedback](#)

Contact

6555 W. Good Hope Rd
Milwaukee, WI 53223

Phone: 888-250-3082
Hours: 7:00am–5:00pm CT
Monday–Friday

Brady (NYSE:BRC) is a manufacturer of complete solutions that identify and protect people, products and places. Brady's products help customers increase safety, security, productivity and performance and include high-performance labels, signs, safety devices, printing systems and software.



2020 © Brady Worldwide, Inc.