




[Labels](#) / [Labels by Portable Printer](#) / [TLS PC Link Labels](#) /

BMP61 BMP71 TLS 2200 UltraTemp 1-Mil Matte Polyimide Labels

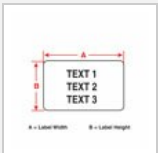

## BMP61 BMP71 TLS 2200 UltraTemp 1-Mil Matte Polyimide Labels

**Part Number:**

PTL-28-719

**Label/Tape Size:**

0.25 in H x 1.5 in W

**Material:**

Polyimide

**For Use with Printer:**

BMP®61 Labeling System, BMP®71 Label Printer, TLS 2200® Thermal Labeling System, TLS-PC LINK™ Thermal Labeling System

**Color:**

White

**Material Number:**

B-719

**ADD TO CART**

1



[Add To Favorites](#)

## PEOPLE ALSO VIEWED

## OVERVIEW

Static Dissipative Polyimide (B-719) withstands wave solder environments and multiple harsh washes for printed circuit board and electronic component preprocess labeling.

- Low profile, high temperature, matte white polyimide material features a static dissipative adhesive and static dissipative release liner
- Surface resistivity values in the recommended range for Dissipative ESD packaging materials as defined by ANSI/ESD S541-2008
- RoHS compliant to 2011/65/EU; UL Approved; Meets requirements of MIL-STD-202G, Method 215K
- Service temperature of -94 to 212° F (-70 to 100° C)

## SPECIFICATIONS

Material Number	<b>B-719</b>
-----------------	--------------

Dimensions	0.25 in H x 1.5 in W
UOM	Roll
Finish	Matte
Label/Tape Size	0.25 in H x 1.5 in W
Maximum Service Temperature °F	572 °F
Minimum Service Temperature °F	-94 °F
Pre-Printed Areas on Label	Colored Write-On Area
Product Number	134297
UPC	754473924799
Quantity per Roll	750
Quantity per Row	1
Thickness	0.0033 in
Adhesive Type	Acrylic
Color	White
For Use with Printer	BMP®61 Labeling System, BMP®71 Label Printer, TLS 2200® Thermal Labeling System, TLS-PC LINK™ Thermal Labeling System
Header	No Header
Label/Media Format	Roll
Label Properties	Heat Resistant Labels, Permanent Adhesive Labels
Material	Polyimide
Material Properties	Low Profile, Static-dissipative
Print Technology	Thermal Transfer
Shape	Rectangle
Suggested Ribbon Series	R6000

## Solutions

[Floor Marking Guide](#)

## Services

[Lockout Tagout Services](#)

## Help

[Contact Us](#)

## Resources

[Find a Distributor](#)

GHS Label Compliance  
Lockout Tagout Compliance  
Arc Flash Labeling Requirements  
Cable and Wire Label Options  
Product and Barcode Labeling  
Brand Protection Solutions

Arc Flash Services  
Confined Space Services  
Visual Workplace Services  
Hazcom GHS Services  
Software Programming & Integration  
Label Template & File Conversion  
Printer Use & Training  
Printer Preventative Maintenance  
Toll and Custom Coating  
Authentication & Tracking Services

Knowledge Center  
Printer Drivers & Firmware  
Brady Software Updates  
Safety Data Sheets  
Technical Data Sheets  
WEEE-RoHS Compliance  
Product Certification  
Printer Registration

Design Custom Safety Signs  
Printer Selection Tool  
Label Selection Tool  
Digital Catalog  
Request a Catalog  
Interactive Facility Map  
EPA e-Manifest Update

## Corporate

[About](#)

[Careers](#)

[Investors](#)

[Privacy Policy](#)

[Terms and Conditions](#)

[Terms of Use](#)

[ISO Certificates](#)

[Protection Solutions](#)

## Other BradyContact Sites

[Distributor Portal](#)


[International Sites](#)

[Safety Services & Software](#)

[Smart ID Brand Protection Solutions](#)

6555 W. Good Hope Rd.  
Milwaukee, WI 53223  
Phone: 888-250-3082  
Hours: 7am-6pm CT  
Monday - Thursday;  
Friday 7am-5pm CT

Brady (NYSE:BRC) is a manufacturer of complete solutions that identify and protect people, products and places. Brady's products help customers increase safety, security, productivity and performance and include high-performance labels, signs, safety devices, printing systems and software.

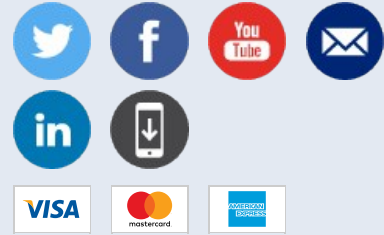

2018 © Brady Worldwide, Inc.