



[Labels](#) / [Labels by Portable Printer](#) / [TLS PC Link Labels](#) /  
BMP61 M611 TLS 2200 Self-Laminating Vinyl Wire and Cable Labels

# BMP61 M611 TLS 2200 Self-Laminating Vinyl Wire and Cable Labels





## Product Highlights:

**Label/Tape Size:**

1.5 in H x 1.5 in W

**Material:**

Vinyl

**Color:**

Red/Translucent

**Material Number:**

B-427

**For Use with Printer:**

BMP®61 Labeling System, BMP®71 Label Printer, BradyPrinter™ M611, TLS 2200® Thermal Labeling System, TLS-PC LINK™ Thermal Labeling System

**Printer and Label Applications:**

Wire & Cable

**Part Number:**

PTL-32-427-RD


ADD TO CART

1



## Add To Favorites

People Also Viewed

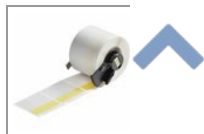

## Overview

Self-Laminating Vinyl (B-427) is an excellent material for wire and cable identification. This material has good clarity, conformability and is self-extinguishing.

- Provided in a self-laminated format with a white printable zone and translucent overlaminating area to protect text
- Durable, permanent acrylic adhesive has outstanding water and oil resistance
- UL approved
- Service temperature of -40°F to 158°F (-40°C to 70°C)

## Specifications

Material Number	<b>B-427</b>
Calculated Country Of Origin	US - All trade information (i.e. Country of Origin, Harmonized Schedule code, and/or Export Control Classification Number) and related assistance provided by Brady Corporation and its affiliates is provided for informational purposes only and is subject to change without notice. Any use of such information by you is without recourse to Brady Corporation or its affiliates and is at your own risk. This information is not provided as legal advice or as a substitute for obtaining specific legal advice. If you have any questions regarding your specific situation, you should consult your attorney.
Catalog Page #	<b>338</b>
Dimensions	1.5 in H x 1.5 in W

UOM	Roll of 250 Labels
Finish	Matte
Indoor or Outdoor Use	Outdoor Use
Label/Tape Size	1.5 in H x 1.5 in W
Maximum Service Temperature °F	140 °F
Maximum Wire Gauge	4 gauge
Minimum Service Temperature °F	-94 °F
Minimum Wire Gauge	10 gauge
Overlaminated Included	Overlaminated Included
Pre-Printed Areas on Label	Colored Write-On Area
Printable Area Dimensions	0.5 in H x 1.5 in W
Printable Area Height	0.5 in
Printable Area Width	1.5 in
Product Number	18600
UPC	662820186007
Quantity per Roll	250
Quantity per Row	1
Secondary Label Included	Secondary Label is Not Included
Thickness	0.004 in
Trade Name	BMP®61 BMP®71 TLS 2200® TLS-PC Link™
Unit Price	/Label
Adhesive Type	Acrylic
Applications	Cable & Wire Marking, Panel Labeling, Voice & Data ID
Color	Red/Translucent
For Use with Printer	BMP®61 Labeling System, BMP®71 Label Printer, BradyPrinter™ M611, TLS 2200® Thermal Labeling System, TLS-PC LINK™ Thermal Labeling System
Header	No Header
Label/Media Format	Roll
Label Properties	Self Laminating Labels & Wraps
Language	No Text
Material	Vinyl
Material Properties	Flame-retardant, Self-Laminating

Printer and Label Applications	Wire & Cable
Print Technology	Thermal Transfer
Resistance Properties	Chemical-Resistant, Humidity-Resistant, Oil-Resistant, Water-Resistant, Weather-Resistant
Shape	Square
Suggested Ribbon Series	R4300, R6200

## Solutions

[Floor Marking Guide](#)  
[GHS Label Compliance](#)  
[Lockout Tagout Compliance](#)  
[Arc Flash Labeling Requirements](#)  
[Cable and Wire Label Options](#)  
[Product and Barcode Labeling](#)

## Services

[Lockout Tagout Services](#)  
[Arc Flash Services](#)  
[Confined Space Services](#)  
[Software Programming & Integration](#)  
[Label Template & File Conversion](#)  
[Printer Use & Training](#)  
[Printer Preventative Maintenance](#)  
[Toll and Custom Coating](#)  
[Authentication & Tracking Services](#)

## Help

[Contact Us](#)  
[Website Feedback](#)  
[Knowledge Center](#)  
[Printer Drivers & Firmware](#)  
[Brady Software Updates](#)  
[Safety Data Sheets](#)  
[Technical Data Sheets](#)  
[WEEE-RoHS Compliance](#)  
[Product Certification](#)  
[Printer Registration](#)

## Resources

[Find a Distributor](#)  
[Design Custom Safety Signs](#)  
[Create Custom THT Labels](#)  
[Printer Selection Tool](#)  
[Label Selection Tool](#)  
[Digital Catalog](#)  
[Request a Catalog](#)  
[Interactive Facility Map](#)  
[EPA e-Manifest Update](#)

### Corporate

[About](#)  
[Careers](#)  
[Investors](#)  
[Privacy Policy](#)  
[Terms and Conditions](#)  
[Terms of Use](#)  
[ISO Certificates](#)

### Other BradyContact Sites

[Distributor Portal](#)  
[International Sites](#)  
[Safety Services & Software](#)  
[Brand Protection Solutions](#)

6555 W. Good Hope Rd.  
 Milwaukee, WI 53223  
 Phone: 888-250-3082  
 Hours: 7am-6pm CT  
 Monday - Thursday;  
 Friday 7am-5pm CT

**Brady (NYSE:BRC) is a manufacturer of complete solutions that identify and protect people, products and places. Brady's products help customers increase safety, security, productivity and performance and include high-performance labels, signs, safety devices, printing systems and software.**



2018 © Brady Worldwide, Inc.