

I.D. PRO[®] PLUS PRINTER ACCESSORIES

www.BradyID.com

I.D. PRO[®] Plus
WIRE MARKER PRINTER


Brady continues to manufacture and fully stock the complete range of labels, sleeves and accessories for the I.D. Pro[™] Plus Printer!



U.S. Patent Number D409,230

Description	Part#	Price Each
Hard Side Carrying Case	IDPRO-HC	\$46.73
12-volt Battery Charger	IDPRO-BC12V	\$27.80
Battery Pack	IDPRO-BP	\$46.73
Battery Charger	IDPRO-BC	\$21.00
Black High-Performance Ribbon for PermaSleeve [™] and DuraSleeve [™]	R5300	\$13.15
Black High-Performance Ribbon for all labels and BradySleeve [™] (Lighter Print more Smear resistant)	R7300	\$13.15

Sign And Label Printers

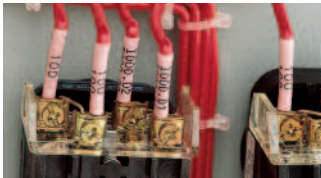

Adhesive Wire Marking Labels for I.D. Pro[®] Plus

- Labels are designed for use with the I.D. Pro[™] Plus Portable Printer
- Highly durable and easily visible; perfect for all your on-site label or wire marking applications

Label Material	Labels per Roll	Approx. Wire Gauge	Label Dimensions Inch (mm)		Max. Lines of Print	Maximum Characters Across		Part#	Price
			Width	Height		Large	Small		
Nylon Cloth, Permanent Adhesive	500	16-22	.5(12.7)	.5(12.7)	3	3	4	WML-305-499	\$58.67
General-Purpose Vinyl Cloth	500	16-22	.5(12.7)	.5(12.7)	3	3	4	WML-305-502	\$56.88
Nylon Cloth, Permanent Adhesive	250	10-16	.5(12.7)	.75(19.05)	4	3	4	WML-505-499	\$37.06
General-Purpose Vinyl Cloth	250	10-16	.5(12.7)	.75(19.05)	4	3	4	WML-505-502	\$35.92
Nylon Cloth, Permanent Adhesive	250	10-16	1.0(25.4)	.75(19.05)	4	7	10	WML-511-499	\$44.26
General-Purpose Vinyl Cloth	250	10-16	1.0(25.4)	.75(19.05)	4	7	10	WML-511-502	\$42.97
Nylon Cloth, Permanent Adhesive	250	10-12	.5(12.7)	1.0(25.4)	6	3	4	WML-705-499	\$39.83
General-Purpose Vinyl Cloth	250	10-12	.5(12.7)	1.0(25.4)	6	3	4	WML-705-502	\$38.68
Nylon Cloth, Permanent Adhesive	250	10-12	1.0(25.4)	1.0(25.4)	6	7	10	WML-711-499	\$47.71
General-Purpose Vinyl Cloth	250	10-12	1.0(25.4)	1.0(25.4)	6	7	10	WML-711-502	\$46.73
General-Purpose Vinyl Cloth	250	6-10	.5(12.7)	1.25(31.75)	8	3	4	WML-905-502	\$41.97
Nylon Cloth, Permanent Adhesive	250	6-10	1.0(25.4)	1.25(31.75)	8	7	10	WML-911-499	\$51.65
General-Purpose Vinyl Cloth	250	6-10	1.0(25.4)	1.25(31.75)	8	7	10	WML-911-502	\$49.84

Self-Laminating Wire Marker Labels for I.D. Pro[®] Plus

- Vinyl labels feature clear "trailer" that wraps to protect printed text
- Resistant to oil, water, and solvents



Approx. Wire Gauge	Max. Wire Diameter Inch (mm)	Label Dimensions Inch (mm)		Write-on Area Height	Lines of Print	Max. Characters Across		Part#	Price Each
		Width	Height			Large	Small		
10-12	.21(5.3)	.5(12.7)	1.0(25.4)	.375(9.53)	2	3	4	WML-205-292-1	\$33.95
10-14	.185(4.7)	.5(12.7)	.75(19.05)	.4(10.16)	2	3	4	WML-205-292-2S*	\$49.34
10-16	.16(4.1)	.5(12.7)	.75(19.05)	.375(9.53)	2	3	4	WML-205-292-75	\$28.51
10-12	.21(5.3)	1.0(25.4)	1.0(25.4)	.375(9.53)	2	7	10	WML-211-292-1	\$41.81
10-16	.16(4.1)	1.0(25.4)	.75(19.05)	.375(9.53)	2t	7	10	WML-211-292-75	\$37.71
6-10	.26(6.6)	.50(12.7)	1.25(31.75)	.5(12.7)	3	3	4	WML-305-292	\$33.76
6-10	.26(6.6)	.50(12.7)	1.25(31.75)	.52(13.21)	3	3	4	WML-305-292-2S*	\$56.57
6-10	.26(6.6)	1.0(25.4)	1.25(31.75)	.5(12.7)	3	7	10	WML-311-292	\$45.42
6-10	.26(6.6)	1.5(38.1)	1.25(31.75)	.5(12.7)	3	10	15	WML-317-292	\$53.60

*Labels are scored in half, length-wise. The width is only .25"