


Label Index by Size

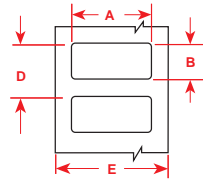

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
3.000" Label Width (Cont.)										
THT-18-408-3	3,000	Paper	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6102
THT-18-422-3	3,000	Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-423-3	3,000	Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-424-3	3,000	Paper	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R4300
THT-18-428-3	3,000	Metallized Polyester	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R4300
THT-18-430-3	3,000	Polyester	Clear	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-433-3	3,000	Removable Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-434-3	3,000	Metallized Polyester	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-435-3	3,000	Glossy Metallized Polyester	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-438-3	3,000	Tamper-Evident Polyester	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R4300
THT-18-449-3	3,000	Polypropylene	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6202
THT-18-483-3	3,000	Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-486-3	3,000	Metallized Polyester	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R4300
THT-18-488-3	3,000	Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R4300
THT-18-489-3	3,000	Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R4300
THT-18-7546-3	3,000	Tamper-Evident Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-7566-3	3,000	Tamper-Evident Polyester	Clear	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-7576-3	3,000	Tamper-Evident Polyester	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
XHT-18-8423-5	5,000	Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6202
XHT-18-8425-5	5,000	Polyolefin	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-19-351-1	1,000	Tamper-Resistant Vinyl	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6202
THT-19-352-1	1,000	Tamper-Resistant Vinyl	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-358-1	1,000	Tamper-Resistant Acetate	Clear	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6202
THT-19-359-1	1,000	Tamper-Resistant Acetate	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6202
THT-19-402-3	3,000	Paper	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6102
THT-19-407-1	1,000	Polyolefin	Clear	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6202
THT-19-408-1	1,000	Paper	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6102
THT-19-422-1	1,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-423-1	1,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-424-1	1,000	Paper	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R4300
THT-19-428-1	1,000	Metallized Polyester	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R4300
THT-19-430-1	1,000	Polyester	Clear	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-432-1	1,000	Polyester	Clear	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-433-1	1,000	Removable Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-434-1	1,000	Metallized Polyester	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-435-1	1,000	Glossy Metallized Polyester	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-438-1	1,000	Tamper-Evident Polyester	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R4300
THT-19-449-1	1,000	Polypropylene	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6202
THT-19-459-1	1,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-483-1	1,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-486-1	1,000	Metallized Polyester	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R4300
THT-19-488-1	1,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R4300
THT-19-489-1	1,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R4300
THT-19-7546-1	1,000	Tamper-Evident Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-7576-1	1,000	Tamper-Evident Polyester	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
XHT-19-8423-3	3,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6202
XHT-19-8425-3	3,000	Polyolefin	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-20-402-11	1,100	Paper	White	1	3.000 (76.20)	5.000 (127.00)	—	5.125 (130.18)	3.200 (81.28)	R6102
THT-20-408-1	1,000	Paper	White	1	3.000 (76.20)	5.000 (127.00)	—	5.125 (130.18)	3.200 (81.28)	R6102
THT-20-424-1	1,000	Paper	White	1	3.000 (76.20)	5.000 (127.00)	—	5.125 (130.18)	3.200 (81.28)	R4300
XHT-20-8425-1	1,000	Polypropylene	White	1	3.000 (76.20)	5.000 (127.00)	—	5.125 (130.18)	3.200 (81.28)	R6202
THT-21-407	1	Polyolefin	Clear	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R6202
THT-21-423	1	Polyester	White	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R6002
THT-21-424	1	Paper	White	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R4300
THT-21-428	1	Metallized Polyester	Silver	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R4300
THT-21-430	1	Polyester	Clear	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R6002

Note: Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).

LABEL INDEX BY SIZE THERMAL TRANSFER LABELS