


Fast-Acting 1/4" x 7/8" Glass Tube Fuses

AGW Series



Dimensions - in

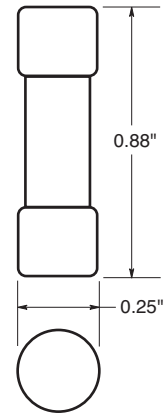

Description

- Fast-acting
- 1/4" x 7/8" (6.3 x 22.2mm) physical size
- Glass tube, nickel-plated brass endcap construction
- Mounts in inline holders HHB, HHH, HRK or 1/4" clips

Ordering

Specify product code


- Insert packaging code prefix before part number.
E.g., BK/AGW-1

Specifications					
Product Code	Voltage Rating Vac	Interrupting Rating (amps) at Rated Voltage AC	Typical DC Cold Resistance (Ω)*	Typical Melt I ² t AC	Typical Voltage Drop (V)**
AGW-1	32	1000	0.1175	7.4	0.152
AGW-1-1/2	32	1000	0.0695	0.220	0.098
AGW-2	32	1000	0.0490	8.44	0.138
AGW-2-1/2	32	1000	0.0346	57.438	0.130
AGW-3	32	1000	0.0318	72	0.119
AGW-4	32	1000	0.0207	7.3	0.024
AGW-5	32	1000	0.0158	105	0.0112
AGW-6	32	1000	0.0124	204.48	0.096
AGW-7-1/2	32	1000	0.0101	213.75	0.104
AGW-10	32	1000	0.0069	406	0.103
AGW-15	32	1000	0.0041	585	0.087
AGW-20	32	1000	0.0029	832	0.078
AGW-25	32	1000	0.0023	1056.25	0.077
AGW-30	32	1000	0.0018	2745	0.076

* DC Cold Resistance (Measured at <10% of rated current)

** Typical Voltage drop (Voltage drop was measured at 25°C ambient temperature at rated current)

Time-Current Curve

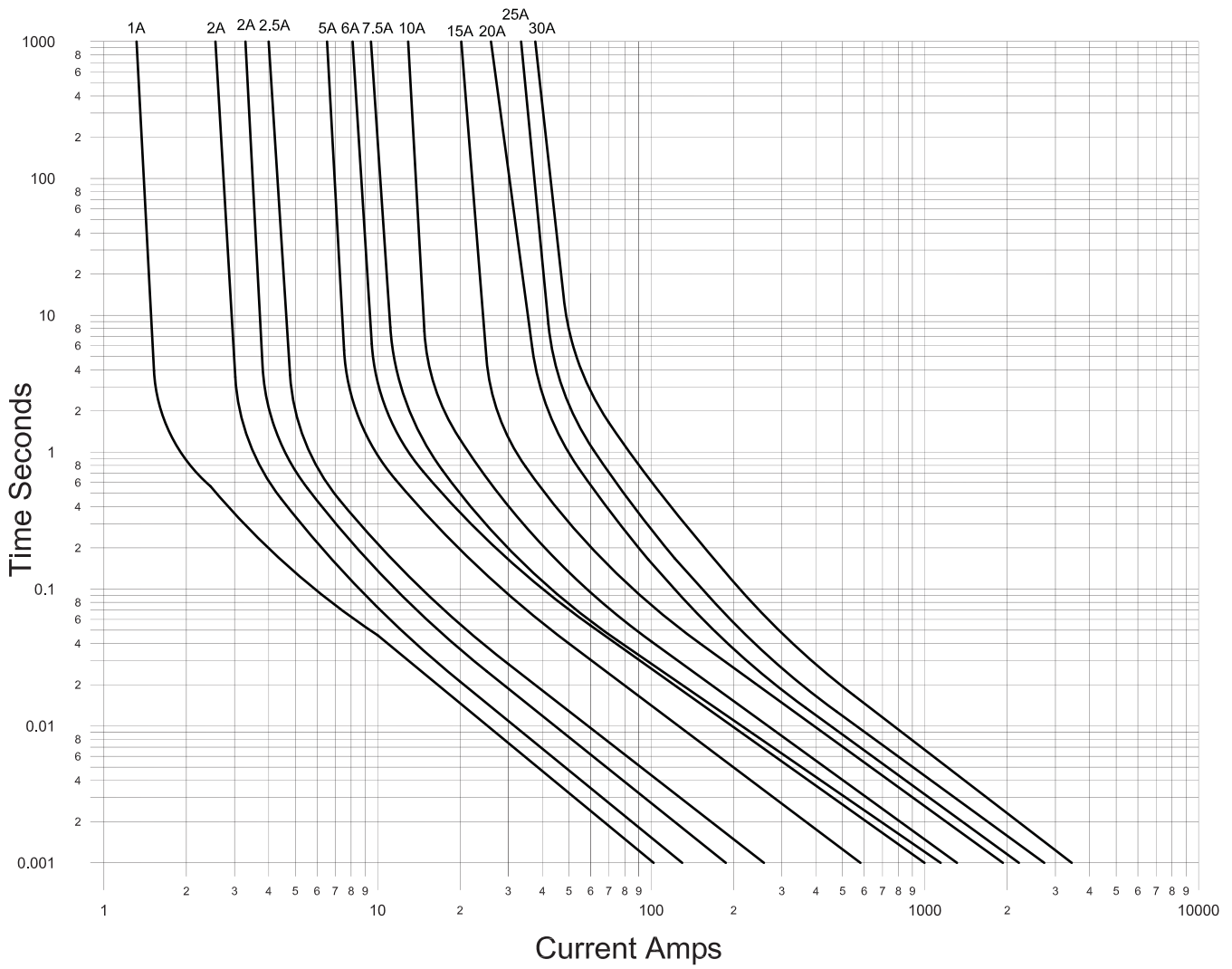

Packaging Code	
Packaging Code	Description
BK	100 fuses packed into a cardboard carton