


- Description** 8 and 11 Pin Round Headers and Mating Enclosures
- Electrical Rating** • 300 Volts, 10 Amps
- Construction** **Contacts** • Brass, Bright Tin Plated
Molding • Headers, High Temperature Thermoset Enclosures, Break Resistant Polycarbonate
- Agency Approvals** • UL recognized, File No. E60008
 • CSA certified, File No. LR29513
 • ROHS

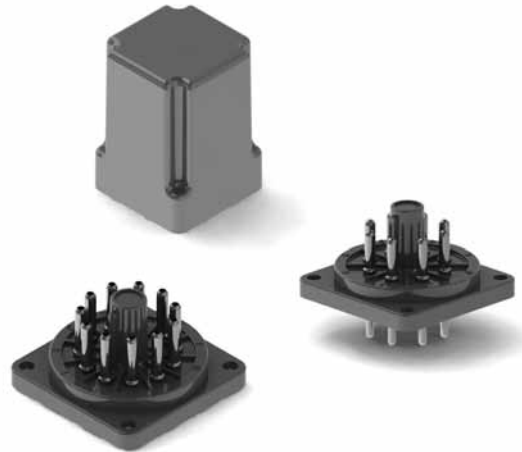

FB/FC Series Ordering Code

Part #	Description
FB08	8 Pin Header (Fig. 1)
FB08D	8 Pin Header (Fig. 2)
FB11	11 Pin Header (Fig. 3)
FB11D	11 Pin Header (Fig. 4)
FCBP	Black Enclosure (Fig. 5)
FCCP	Clear Enclosure (Fig. 5)
FCWP	White Enclosure (Fig. 5)

