

PATCH CORDS - JUMPERS

STANDARD ALLIGATOR CLIP TO SPADE LUG



AVAILABLE IN (12) RED AND (10) BLACK

795-2050-XX 12 inches
795-2051-XX 24 inches
795-2052-XX 36 inches
795-2053-XX 48 inches
795-2054-XX 60 inches
Specify Color

1st END - Plated steel alligator clip with Vinyl boot.

WIRE - #18 AWG, stranded copper wire, PVC insulation.

2nd END - Nickel plated brass spade lug with butyrate handle.

CROSS PATCH PHONE TIP BOTH ENDS .080 PINS/.080 JACKS



AVAILABLE IN BLACK, RED, YELLOW, BLUE & WHITE

795-2225-XX 8 inches
795-2226-XX 12 inches
795-2227-XX 24 inches
795-2228-XX 36 inches
Specify Color

1st END - Stacking cross patch phone tip. Nickel plated brass body

WIRE - #18 AWG, stranded copper wire, PVC insulation.

2nd END - Same as 1st end

STACKING TIP PLUG BOTH ENDS .080 PINS/.080 JACKS



AVAILABLE IN 10 COLORS

795-5045-XX 4 inches
795-5046-XX 8 inches
795-5047-XX 12 inches
795-5048-XX 18 inches
795-5049-XX 24 inches
795-5050-XX 36 inches
795-5051-XX 48 inches
795-5052-XX 60 inches
Specify Color

1st END - Stacking pin tip plug. Gold plated brass body. Gold plated beryllium copper socket. Polypropylene insulation.

WIRE - #20 AWG, stranded copper wire, PVC insulation.

2nd END - Same as 1st end.

LOW PROFILE STACKING TIP PLUG .080 PINS/.080 JACKS



AVAILABLE IN (12) RED AND (10) BLACK

795-2386-XX 4 inches
795-2388-XX 8 inches
795-2389-XX 12 inches
795-2390-XX 18 inches
795-2391-XX 24 inches
795-2392-XX 36 inches
795-2393-XX 48 inches
795-2394-XX 60 inches
Specify Color


1st END - Stacking pin tip plug. Gold plated brass body. Gold plated beryllium copper spring. Polypropylene insulation.

WIRE - #20 AWG, stranded copper wire, PVC insulation.

2nd END - Same as 1st end.

EXTENSION STACKING BANANA PLUGS BOTH ENDS

AVAILABLE IN 10 COLORS

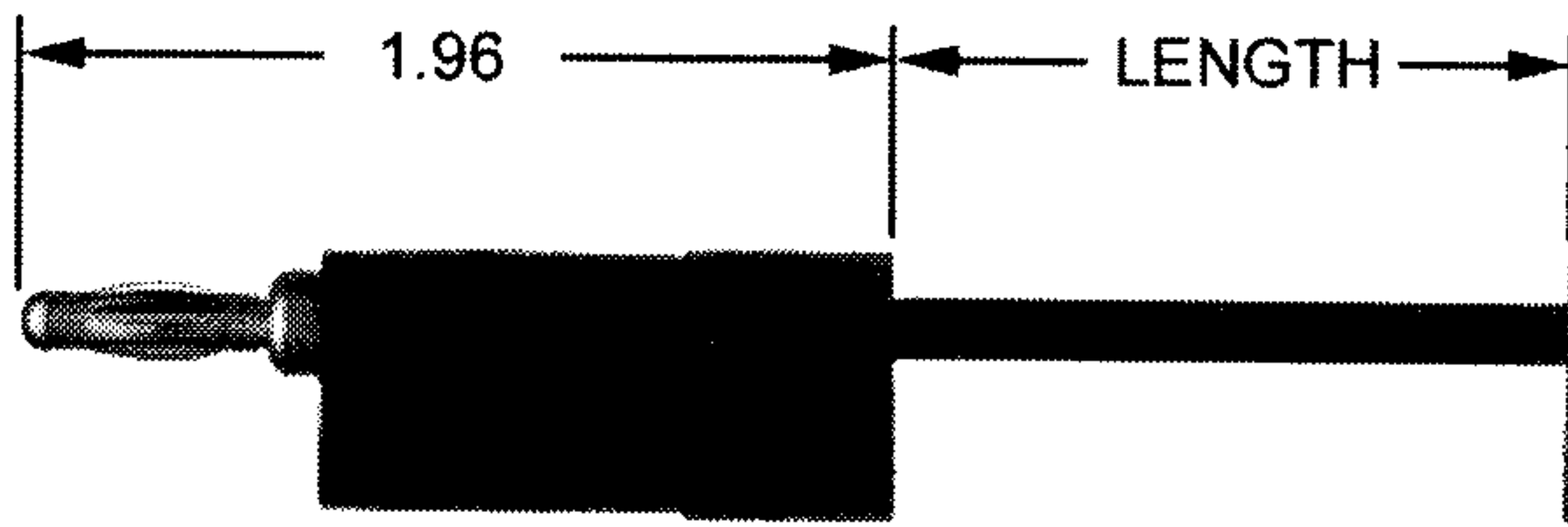

795-2760-XX 4 Inches
795-2761-XX 8 Inches
795-2762-XX 12 Inches
795-2763-XX 18 Inches
795-2764-XX 24 Inches
795-2765-XX 36 Inches
795-2766-XX 48 Inches
795-2767-XX 60 Inches
Specify Color

1st END - Extension stacking banana plug.


Nickel plated brass body.
Nickel plated beryllium copper spring.
Polypropylene insulation.

WIRE - #18 AWG, stranded copper wire, PVC insulation.

2nd END - Same as 1st end.

01-5525-14 TEST LEAD RACK

BLUE ENAMELED FINISHED STEEL
11" LONG, 14 SLOTS

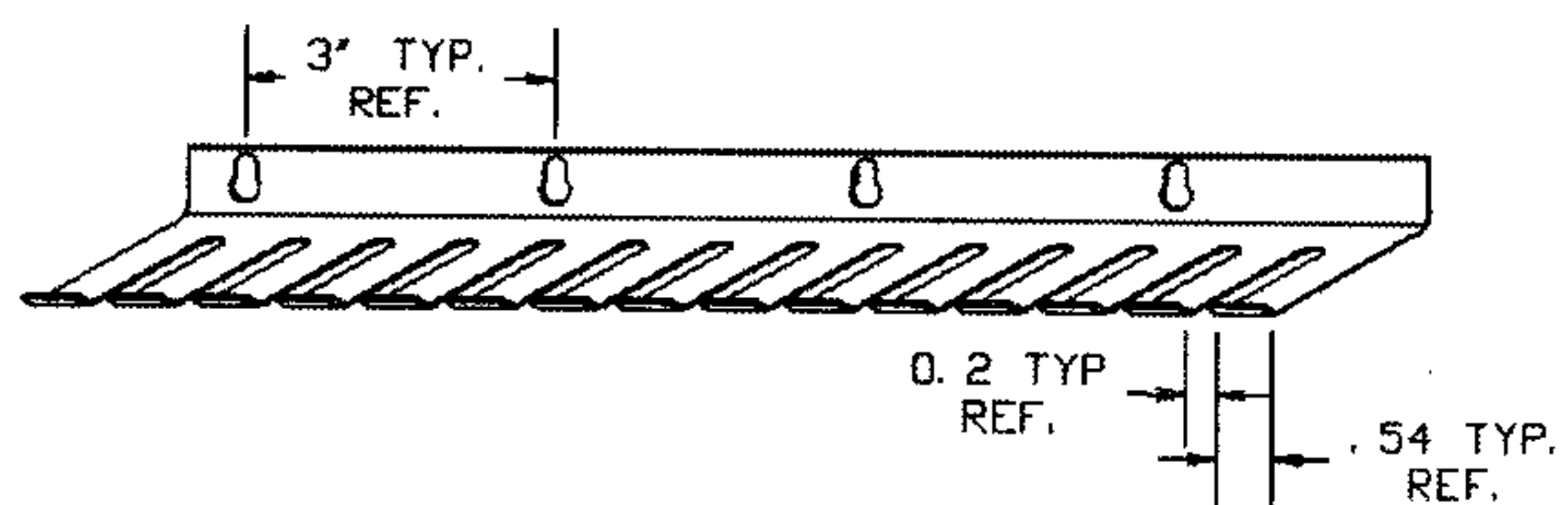

CONCORD

**MAINTAINS LARGE
INVENTORIES TO
SHIP SAME DAY ON
MOST PRODUCTS !**

CONCORD

BLK	BRN	RED	ORN	YEL	GRN	BLU	PUR	GRY	WHT
10	11	12	13	14	15	16	17	18	19