


Standard Size Sealed Rockette Switches

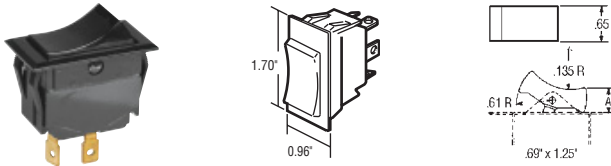


The rocker switches offer a remarkable silicone rubber seal that protects contacts and mechanisms better than conventional seal and boot combinations. The switches resist contaminants such as sand, dust and moisture with both base to frame seal and an actuator seal. **Rated:** 15 A, 125 VAC; 10 A, 250 VAC. **Spade Terminals:** Brass, Concave rocker. Illuminated versions available.

Stock No.	Mfr.'s Type*	Contact Form	Action (Momentary)	EACH		
				1-24	25-49	50+
757-5520	8055K23Z7V	SPST	On-None-Off	9.02	7.13	6.90
757-5521	8055K20Z7V	SPDT	On-Off-On	13.17	10.41	10.84
757-5525	8055K43Z7V	DPST	On-None-Off	11.47	9.26	8.92
757-5522	8055K40Z7V	DPDT	On-Off-On	13.46	10.65	10.28
757-5523	8055K52Z7V	DPDT	(On)-Off-(On)	9.96	8.04	7.77

\*Other terminations available.

Full Size New Generation Rockers

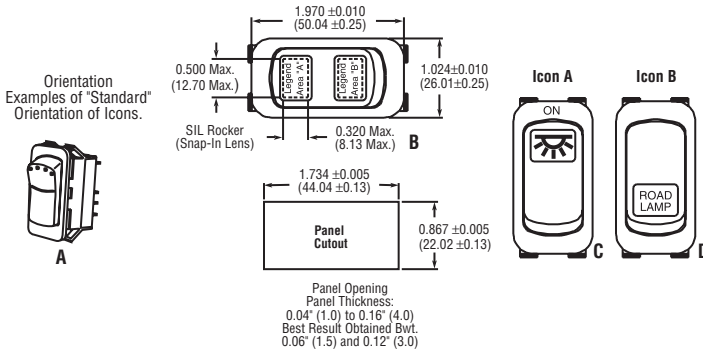

This all new line of rockers offers european styling, ergonomic design with the solid durability you've come to expect from Eaton switches. Rockers and bezels for the NGR series are molded in a soft matte finish. Illuminated and non-illuminated versions are available.

Non-Illuminated (Rated: 15 A @ 125 VAC, 10 A @ 250 VAC, 15 A @ 28 VDC)

Stock No.	Mfr.'s Type	Contact Form	Action (Momentary)	EACH		
				1-24	25-49	50+
757-5539	NGR20011BNO0N	DPST	On-None-Off	9.41	7.44	7.18
757-5540	NGR20031BNO0N	DPDT	On-None-On	12.57	9.94	9.58
757-5541	NGR20041BNO0N	DPDT	On-Off-On	12.83	10.16	9.80
757-5542	NGR20051BNO0N	DPDT	(On)-Off-(On)	12.99	10.29	9.91

Illuminated (Rated: 15 A @ 125 VAC, 10 A @ 250 VAC, 15 A @ 28 VDC)

Stock No.	Mfr.'s Type	Contact Form	Action (Momentary)	EACH		
				1-24	25-49	50+
757-5543	NGR25011BNA0N	DPST	On-None-Off	13.96	11.27	10.85
757-5544	NGR25481BNA0N	DPDT	On-None-On	16.08	12.98	12.50
757-5545	NGR25681BNA0N	DPDT	On-Off-On	17.26	13.95	13.43
757-5546	NGR25881BNA0N	DPDT	(On)-Off-(On)	16.20	13.09	12.60

NGR Rocker Button (Ordered Separately; Does Not Include Lens)



Stock No.	Mfr.'s Type	Fig.	Description	EACH		
				1-24	25-49	50+
757-5399	1D00000000000	A	Black Rocker, No Lens	.88	.71	.65
757-5568	2C000500000500	B	Lens Hole Top/Bottom	1.61	1.33	1.27
757-5569	2A000500000000	C	Lens Hole Top	.87	.69	.66
757-5400	2B000000000500	D	Lens Hole Bottom	.82	.53	.44

NGR Rocker Lens (Ordered Separately)

Stock No.	Mfr.'s Type	Color	EACH		
			1-24	25-49	50+
757-5551	28-5863	Green	.25	.20	.19
757-5552	28-5863-3	Amber	.28	.22	.20
757-5553	28-5863-2	Red	.23	.18	.17

Stock No.	Mfr.'s Type	Description	EACH		
			1-24	25-49	50-99
757-5401	17-21543	Panel Plug	2.24	2.04	1.86
757-5402	17-21160	End Section	2.13	1.93	1.77
757-5403	17-21159	Center Section	2.13	1.93	1.77
757-5404	28-5637-2	10-Hole Connector	.87	.80	.73
757-5405	28-5940	12-Hole Connector	.89	.80	.74

Midsize Snap-In AC Rocker Switches

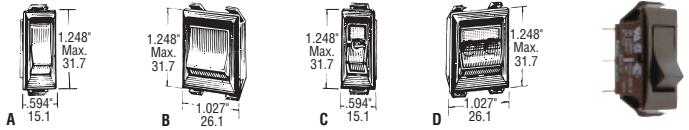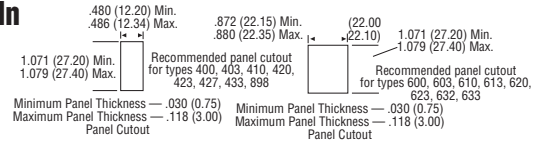

Matte Finish/Rounded Bezel/Contoured Rocker — 1500/2500 Series

These switches come in lighted and non-lighted versions in a variety of standard or custom colors. They are UL, CSA and VDE approved. Ideal applications include appliances, electronic instrumentation, data processing, communications, medical and office equipment. Options available are legend stamping, solder lugs, independent lamp circuits, special and matched colors, high inrush capabilities. Aesthetically pleasing yet ruggedly functional with traditional Eaton quality, these switches are ideal for up-front applications where both appearance and reliability are required.

Non-Illuminated Type (Rated: 15 A, 125 V; 10 A, 250 V)

Stock No.	Mfr.'s Type	Fig.	Contact Form	Action (Momentary)	EACH		
					1-49	50-99	100-249
757-5013	150011E	A	SPST	On-None-Off	1.13	1.00	.83
757-5014	150111E	A	SPST	(On)-None-Off	1.85	1.62	1.34
757-5015	150211E	A	SPDT	On-None-On	2.34	2.05	1.71
757-5016	150411E	A	SPDT	On-Off-On	2.42	2.13	1.77
757-5017	250011E	B	DPST	On-None-Off	1.85	1.63	1.36
757-5018	250111E	B	DPST	(On)-None-Off	2.33	2.06	1.73
757-5019	250211E	B	DPDT	On-None-On	2.39	2.08	1.75

Illuminated Type (Rated: 15 A, 125 V; 10 A, 250 V)


Stock No.	Mfr.'s Type*	Fig.	Contact Form	Action	Lens Color	EACH		
						1-49	50-99	100+
757-5007	1500R11E	C	SPST	On-None-Off	Red	3.51	3.14	2.60
757-5008	1500A11E	C	SPST	On-None-Off	Amber	2.67	2.39	2.02
757-5009	1500G11E	C	SPST	On-None-Off	Green	2.91	2.61	2.20
757-5010	2500R11E	D	DPST	On-None-Off	Red	3.18	2.87	2.35
757-5011	2500A11E	D	DPST	On-None-Off	Amber	3.74	3.36	2.81
757-5012	2500G11E	D	DPST	On-None-Off	Green	3.20	2.87	2.41

\*Other lamp voltages are available.

Rocker Switches with On-Off Legends (Rated: 15 A, 125 V; 10 A, 250 V)

Stock No.	Mfr.'s Type	Fig.	Contact Form	Action	EACH		
					1-49	50-99	100+
757-5020	1500-11E671	A	SPST	On-None-Off	1.48	1.30	1.09
757-5021	2500-11E735	B	DPST	On-None-Off	2.25	1.89	1.57

Gloss Finish/Flat Bezel/Two-Face Rocker — 1600/2600 Series

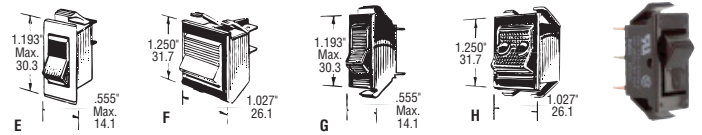

Non-Illuminated (Rated: 16 A, 125 VAC/250 VAC)

Stock No.	Mfr.'s Type	Fig.	Contact Form	Action (Momentary)	EACH		
					1-49	50-99	100+
757-3012	160011E	E	SPST	On-None-Off	1.45	1.27	1.05
757-3013	160111E	E	SPST	(On)-None-Off	1.48	1.31	1.11
757-3014	160211E	E	SPDT	On-None-On	1.83	1.61	1.36
757-3015	160411E	E	SPDT	On-Off-On	1.73	1.52	1.26
757-3016	260011E	F	DPST	On-None-Off	1.81	1.60	1.33
757-3017	260111E	F	DPST	(On)-None-Off	2.28	2.00	1.66
757-3018	260211E	F	DPDT	On-None-On	4.33	3.89	3.21
757-3019	260411E	F	DPDT	On-Off-On	2.95	2.66	2.20

Illuminated (Rated: 16 A, 125 VAC/250 VAC)

Stock No.	Mfr.'s Type	Fig.	Contact Form	Action	Lens Color	EACH		
						1-49	50-99	100+
757-3020	1600R11E	G	SPST	On-None-Off	Red	2.70	2.41	2.05
757-3021	1600A11E	G	SPST	On-None-Off	Amber	2.85	2.55	2.15
757-3024	1600G11E	G	SPST	On-None-Off	Green	2.85	2.55	2.15
757-3025	2600R11E	H	DPST	On-None-Off	Red	4.19	3.77	3.10
757-3026	2600A11E	H	DPST	On-None-Off	Amber	3.46	3.11	2.56
757-3027	2600G11E	H	DPST	On-None-Off	Green	3.20	2.88	2.37

High Inrush "H" Series (Rated: 22 A, 125 VAC; 16 A, 250 VAC)

Stock No.	Mfr.'s Type	Fig.	Contact Form	Action	Description	EACH		
						1-49	50-99	100+
757-3028	1600H11E	E	SPST	On-None-Off	Black Gloss	1.62	1.43	1.18
757-3029	1600HR11E	G	SPST	On-None-Off	Red Lens, 125 V Neon	2.89	2.60	2.18
757-3030	2600H11E	F	DPST	On-None-Off	Black Gloss	2.79	2.45	2.03
757-3031	2600HR11E	H	DPST	On-None-Off	Red Lens, 125 V Neon	3.18	2.85	2.35