

CGB1013 portable cord connectors

Gland type:

- Portable cord connector

Cable type:

- Non-armored

Features:


- Standard neoprene seal suitable for use in operating temperatures -25°C to 40°C
- Available with NPT threads

Certifications and compliances:

- cULus Listed - UL File No. E-23223
- Suitable for use in Class I, Division 2 hazardous locations when installed in accordance with NEC501.10(B)(2)

Standard materials and finishes:

- Body – steel with zinc electroplate and chromate finish coat
- Gland nut – aluminum

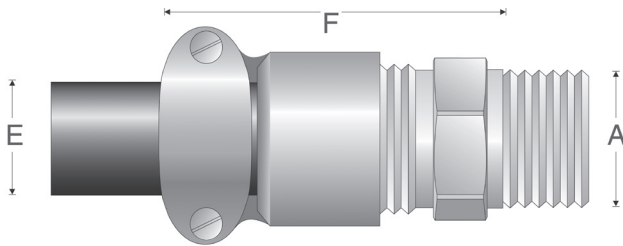

Ordering information:

Entry thread size (A)		Outer sheath (E)	
NPT size	Cat. #	Min.	Max.
1/2"	CGB1013	0.312	0.437
1/2"	CGB1014	0.375	0.500
1/2"	CGB1015	0.500	0.625
3/4"	CGB2013	0.312	0.437
3/4"	CGB2014	0.375	0.500
3/4"	CGB2015	0.500	0.625

All dimensions in inches.

Ordering information – CGB with oil impregnated flax packing:

NPT size	Cable dia.	Cat. #
1/2"	0.250-0.625	CGB1
3/4"	0.594-0.688	CGB2
1"	0.688-0.968	CGB3
1 1/4"	0.906-1.219	CGB4
1 1/2"	1.219-1.438	CGB5