

Weatherproof outlet boxes

Features:

- Durable die cast aluminum construction for long product life
- Powder paint finish for corrosive environments
- Boxes supplied with required installation hardware
- Tapered NPT hubs

Standard materials and finishes:

- Boxes – die cast aluminum
- Self-closing covers – zinc die cast
- Toggle switch covers – stamped aluminum
- Blank covers – steel

Certifications and compliances:

- UL Standard UL514A
- UL Listed File No. E-15022
- cUL Standard CSA C22.2 No 18.1-04
- Suitable for wet locations

SINGLE GANG – 18.0 CUBIC INCH CAPACITY – 2" DEEP CAST ALUMINUM – UL LISTED FOR WET LOCATIONS




TP7010 - TP7018



TP7026, TP7034



TP7042, TP7050

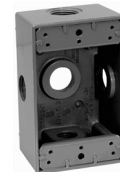

TP7058, TP7066

Cat. #	Description	Outlet holes	Color	Unit qty.	Wt. lbs. per 100
TP7010	With lugs	3 - 1/2"	Gray	50	58.3
TP7011	With lugs	3 - 1/2"	White	50	58.3
TP7012	With lugs	3 - 1/2"	Bronze	50	58.3
TP7018	With lugs	3 - 3/4"	Gray	50	58.3
TP7026	With lugs	4 - 1/2"	Gray	50	58.3
TP7034	With lugs	4 - 3/4"	Gray	50	58.3
TP7042	With lugs	5 - 1/2"	Gray	50	58.3
TP7050	With lugs	5 - 3/4"	Gray	50	58.3
TP7058	Side entry, with lugs	5 - 1/2"	Gray	50	58.3
TP7066	Side entry, with lugs	5 - 3/4"	Gray	50	58.3

SINGLE GANG – 24.0 CUBIC INCH CAPACITY – 2 5/8" DEEP CAST ALUMINUM – UL LISTED FOR WET LOCATIONS



TP7074, TP7078, TP7082

Cat. #	Description	Outlet holes	Color	Unit qty.	Wt. lbs. per 100
TP7074	With lugs	3 - 1/2"	Gray	25	80
TP7078	With lugs	3 - 3/4"	Gray	25	80
TP7082	With lugs	3 - 1"	Gray	25	80

Weatherproof

Weatherproof outlet boxes

TWO GANG – 30.5 CUBIC INCH CAPACITY

2" DEEP

CAST ALUMINUM – UL LISTED FOR WET LOCATIONS




TP7086 - TP7090



TP7094, TP7098



TP7102, TP7106

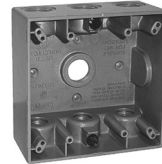

TP7110, TP7114



TP7118, TP7122

Cat. #	Description	Color	Unit qty.	Wt. lbs. per 100
TP7086	3 - 1/2" holes	Gray	10	83.3
TP7087	3 - 1/2" holes	White	10	83.3
TP7088	3 - 1/2" holes	Bronze	10	83.3
TP7090	3 - 3/4" holes	Gray	10	83.3
TP7094	4 - 1/2" holes	Gray	10	83.3
TP7098	4 - 3/4" holes	Gray	10	83.3
TP7102	5 - 1/2" holes	Gray	10	83.3
TP7106	5 - 3/4" holes	Gray	10	83.3
TP7110	7 - 1/2" holes	Gray	10	83.3
TP7114	7 - 3/4" holes	Gray	10	83.3
TP7118	5 - 1/2" holes	Gray	10	83.3
TP7122	5 - 3/4" holes	Gray	10	83.3

TWO & THREE GANG

2 5/8" DEEP

CAST ALUMINUM – UL LISTED FOR WET LOCATIONS



TP7126, TP7130, TP7134



TP7137, TP7138, TP7142



TP7143




TP7144

Cat. #	Description	Color	Capacity Cu. In.	Unit Qty.	Wt. lbs. per 100
Two gang deep weatherproof outlet boxes					
TP7126	5 - 1/2" holes	Gray	37	6	140
TP7130	5 - 3/4" holes	Gray	37	6	140
TP7134	5 - 1" holes	Gray	37	6	140
TP7137	7 - 1/2" holes	Gray	37	6	140
TP7138	7 - 3/4" holes	Gray	37	6	140
TP7142	7 - 1" holes	Gray	37	6	140
Three gang deep weatherproof outlet boxes					
TP7143	7 - 3/4" holes	Gray	59	5	159
TP7144	7 - 1" holes	Gray	59	5	159

Weatherproof

Weatherproof outlet boxes

Dimensions (in inches):

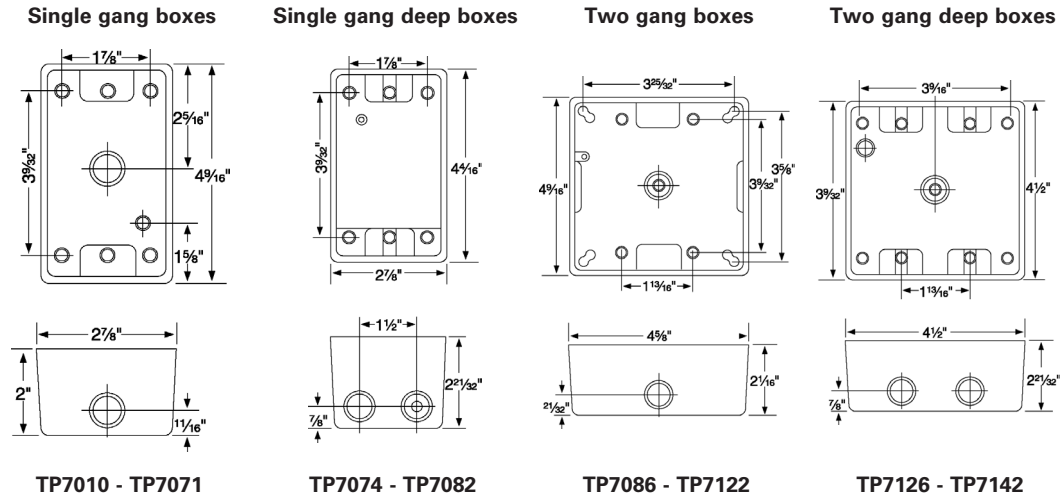

ONE & TWO GANG WEATHERPROOF EXTENSIONS

1" DEEP, DIE CAST ALUMINUM EXTENSION RING
 GASKET & MOUNTING SCREWS INCLUDED WITH COVER
 UL LISTED FOR WET LOCATIONS



TP7120



TP7123

Cat. #	Description	Color	Capacity cu. in.	Unit qty.	Wt. lbs. per 100
TP7120	Single gang	Gray	9	25	27.2
TP7123	Two gang	Gray	10	10	27.2

EXTENSION ADAPTER

DIE CAST ALUMINUM
 MOUNTING SCREW & GASKET INCLUDED WITH COVER
 UL LISTED FOR WET LOCATIONS



Cat. #	Description	Color	Capacity cu. in.	Unit qty.	Wt. lbs. per 100
TP7173	4 - 1/2" holes	Gray	9.5	25	23.6
TP7174	4 - 3/4" holes	Gray	13.0	25	27.8

Weatherproof outlet boxes

4" ROUND – 15.5 CUBIC INCH CAPACITY

1½" DEEP, DIE CAST ALUMINUM, UL LISTED FOR WET LOCATIONS

- GROUND SCREW PROVIDED WITH BOX
- GASKET & MOUNTING SCREWS INCLUDED WITH COVER




TP7152



TP7146



TP7147 - TP7151

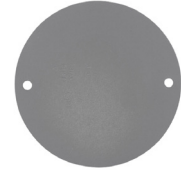


TP7158

Cat. #	Side holes	Back hole	Color	Unit qty.	Wt. lbs. per 100
TP7146	4 - ½"	½"	Gray	25	79.2
TP7148	4 - ½"	½"	White	25	79.2
TP7149	4 - ½"	½"	Bronze	25	79.2
TP7150	4 - ¾"	¾"	Gray	25	79.2
TP7158	Blank cover plate	-	Gray	50	20.8
With blank plate					
TP7147	4 - ½"	½"	Gray	24	100.0
TP7151	4 - ¾"	¾"	Gray	24	100.0
1½" deep round weatherproof outlet box extension (18.3 Cubic inch capacity)					
TP7152	4 - ½"	-	Gray	25	58.3


Dimensions (in inches):

Round boxes

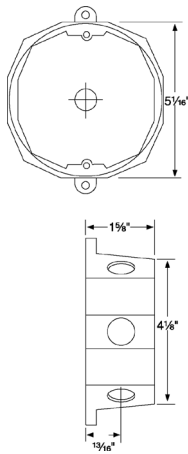

TP7146

Extension rings & flanged boxes

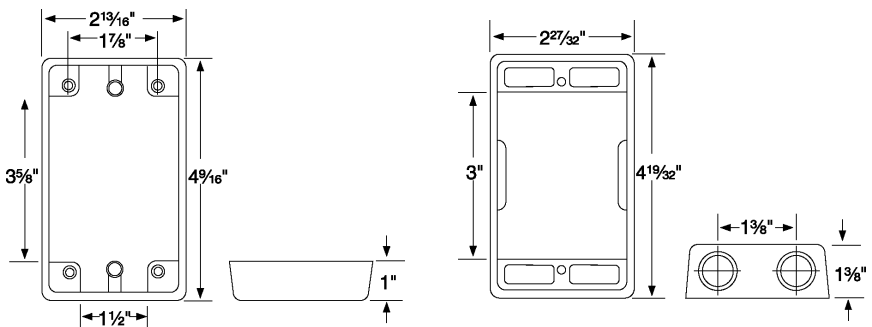

TP7120

TP7120