

In-stock products

CROUSE-HINDS
SERIES

Quick Delivery Service




EATON

Powering Business Worldwide

Our Quick Delivery Service helps you to react flexibly.

Do you need a specific product quickly? Our express delivery service is the perfect solution

In addition to our excellent quality, we now offer a quick delivery service for a range of products. This means that even if you have tight deadlines, everything can still be dealt with smoothly.

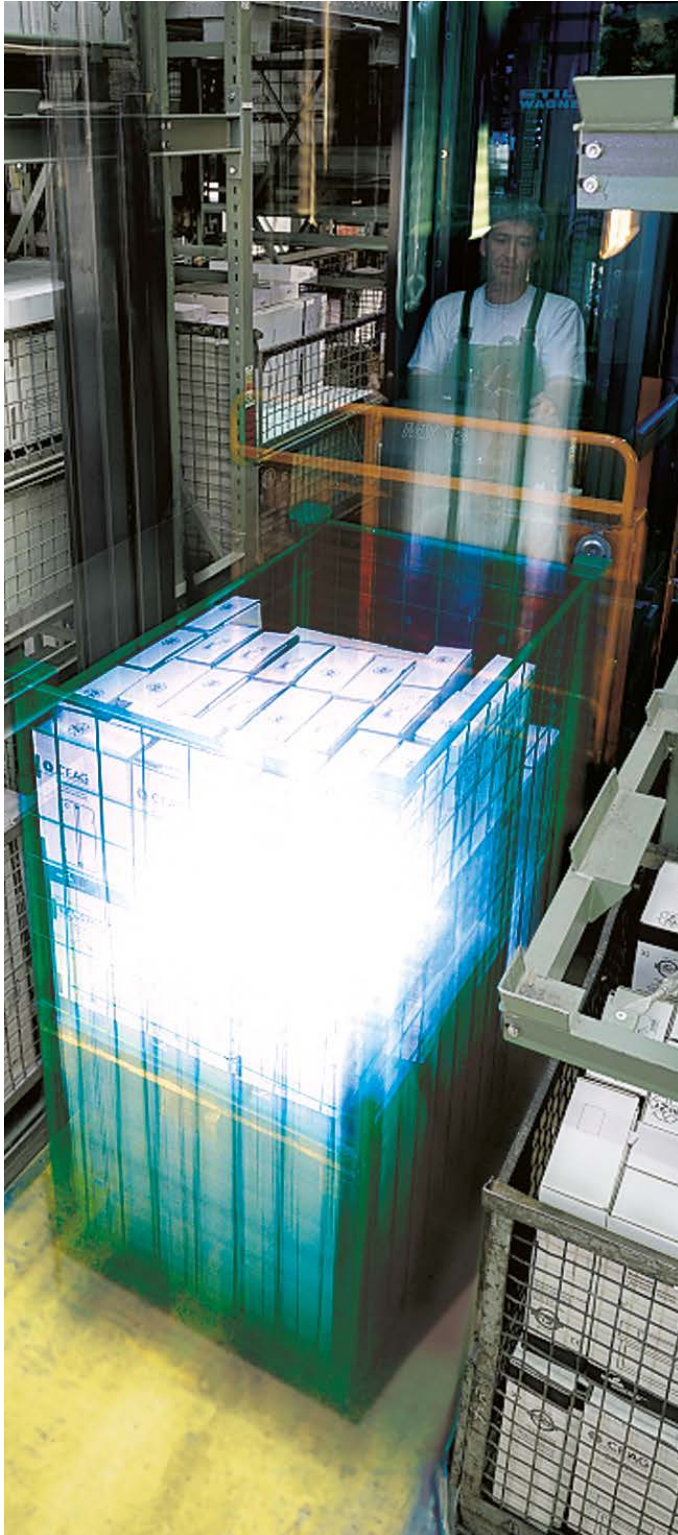

Crouse-Hinds Series

The new name in industrial safety and explosion protection. Eaton is dedicated to ensuring that reliable, efficient and safe power is available when it's needed most. With excellent knowledge of electrical power management across industries, experts at Eaton deliver customised, integrated solutions to solve our customers' most critical challenges.

Furthermore we offer a very special delivery service for a range of products that enables you to keep your appointments also for difficult orders.

Our efficient logistics chain ensures the delivery of our equipment:

- promptly
- reliably
- safely

We deliver electrical devices – lighting, switchgear and connectivity solutions – directly to where you need them.

We have included the most important product groups in our Quick Delivery Service program.

An overview of our Quick Delivery Service:

If your order is received in our customer service centre before 12.00 midday, we ensure that the goods are dispatched within three working days*, without any extra charge. This special service is available for the following products.

* This service is available for reasonable quantities.

We offer reliable service and know-how.

Engineered Safety & Productivity



Is electrical explosion protection an important part of your offering or operation, but not your core business? Then you need a competent partner you can rely on in this area.

In addition to product documentation and certificates you require, we also offer comprehensive service and application engineering support.

We take into account the special features of your requirements and offer you tailor-made solutions with our standard products or with specially configured solutions. Our sales engineers and technicians in our customer service centre give you professional, comprehensive and personalized advice when selecting the right devices. With us, you have a personal contact person who, in consultation with our expert teams in development, project planning, production and product management, develops the

best solution for you and your operation.

In addition to our Quick Delivery Service, we also offer our customers the opportunity to access information on the status of the order processing, delivery times, logistics etc. at any time, so that you can react flexibly to changes in your business.

We can also serve you on-site, advise you on installation, carry out inspections and approvals and offer training courses. This enable us that our products are used optimally and no friction losses caused by lack of information.

And it goes without saying that after the project is complete, you will be able to take advantage of our after-sales service. Whether you wish to re-order, ask any questions you may have or make a complaint, we are always on hand to help.



Your professional partner for explosion protection:

Eaton's electrical business is a global leader with expertise in power distribution and circuit protection, backup power protection, control and automation, lighting and security, structural solutions and wiring devices, solutions for harsh and hazardous environments and engineering services. Eaton is positioned through its global solutions to answer today's most critical electrical power management challenges.

CEAG Products from Eaton's Crouse-Hinds Series for IEC-applications manufactured in Europe are well-known since more than a century. North Sea offshore facilities as well as modern chemical plants rely on the well-proven and innovative solutions of CEAG products.



Quick Delivery Service

If your order is received in our customer service centre before 12.00 noon, we ensure that the goods are dispatched within three working days, without any extra charge.

For contact information: www.crouse-hinds.de

Product group

Portable Ex-Lamps



Order-No.	Description
1 1118 009 410	Handlamp HE 9 Basic LED
1 1147 000 810	LED-Searchlight SEB 10 L (comming soon)
1 1147 000 820	LED-Searchlight SEB 10 (comming soon)
1 1147 009 001	Searchlight SEB 9L
1 1147 009 002	Searchlight SEB 9
1 1358 000 001	Torchlight Stabex mini
1 1360 000 006	Torchlight Stabex mini LED
1 1359 001 001	Torchlight Stabex HF LED
1 1359 000 070	Halogen-lamp 2,8 V/0,5 A for Stabex HF/HF-L
1 1518 009 111	Plug-in charger for HE 9 LED
1 1145 000 792	vehicle charger 90 for SEB 8, 9 and 10
1 1540 000 443	Charger LG 443 for SEB 8, 9 and 10
1 2061 000 040	Halogen-lamp with double bulb 5.5 V/5.5 W for Ex-searchlight SEB 9 and SEB 8
2 1147 701 000	NICD-Accumulator (for SEB 8) 4 X 7 AH CEAG


Ex-Fluorescent Light Fittings



1 2265 502 101	Linear light fitting eLLK 92 LED 400 1/6 M25K 110-254V 5600K
1 2265 502 111	Linear light fitting eLLK 92 LED 400 2/6 M20M 110-254V 5600k
1 2266 502 103	Linear light fitting eLLK 92 LED 800 2/6 M25K 110-254V 5600K
1 2266 502 111	Linear light fitting eLLK 92 LED 800 2/6 M20M 110-254V 5600k
1 2260 885 101	Emergency light fitting eLLK 92018/18 NE 1/6-1
1 2260 885 111	Emergency light fitting eLLK 92018/18 NE 2/6-2M
1 2261 885 101	Emergency light fitting eLLK 92036/36 NE 1/6-1
1 2261 885 103	Emergency light fitting eLLK 92036/36 NE 2/6-2K
1 2261 885 111	Emergency light fitting eLLK 92036/36 NE 2/6-2M
1 2265 875 101	Fluorescent light fitting eLLK 92018/18 1/6-1
1 2265 875 103	Fluorescent light fitting eLLK 92018/18 2/6-2K
1 2265 875 109	Fluorescent light fitting eLLK 92018/18 1/6-1 M
1 2265 875 111	Fluorescent light fitting eLLK 92018/18 2/6-2 M
1 2266 875 101	Fluorescent light fitting eLLK 92036/36 1/6-1
1 2266 875 103	Fluorescent light fitting eLLK 92036/36 2/6-2K
1 2266 875 109	Fluorescent light fitting eLLK 92036/36 1/6-1 M
1 2266 875 111	Fluorescent light fitting eLLK 92036/36 2/6-2 M
1 2267 875 101	Fluorescent light fitting eLLK 92058/58 1/6-1
1 2267 875 103	Fluorescent light fitting eLLK 92058/58 2/6-2K
1 2268 875 101	Pole-mounted fluorescent light fitting eLLM 92018/18 1/6-1K
1 2269 875 101	Pole-mounted fluorescent light fitting eLLM 92036/36 1/6-1K
1 3465 236 001	Fluorescent light fitting nLLK 08036/36 1/3-1 Zone 2
1 3465 236 011	Fluorescent light fitting nLLK 08036/36 2/5 25K Zone 2
1 3465 236 021	Fluorescent light fitting nLLK 08036/36 2/6 20M Zone 2 terminal Z1
1 3465 258 011	Fluorescent light fitting nLLK 08058/58 2/5 25K Zone 2
1 3463 218 023	Linear light fitting LLK 98 LED 600 2/6 M25K 230 V for industrial application
1 3463 236 023	Linear light fitting LLK 98 LED 1200 2/6 M25K 230 V for industrial application

If your order is received in our customer service centre before 12.00 noon, we ensure that the goods are dispatched within three working days, without any extra charge.

For contact information: www.crouse-hinds.de

Product group	Order-No.	Description
Ex-Fluorescent Light Fittings Accessories		
	2 2216 002 000	Protective bowl with gasket for fluorescent light fittings eLLK 92 (36 W) a. nLLK 08 (36 W)
	2 2480 092 000	Fixing materials ceiling mounting bracket D92
	2 2480 472 000	Fixing materials pipe clamp R22 (1 1/2) galvanized, 47 - 51 mm
	2 2710 902 000	Battery set type 2710-02 Ni
	2 2710 904 000	Battery set type 2710-03 NIB
	3 2475 901 012	LED-tube Osram SubstiTube 11 W 840 1200 lm G13
	3 2475 901 015	LED-tube Osram SubstiTube 22 W 840 2500 lm G13
Ex-Emergency and Signal Luminaire		
	1 2191 030 023	Escape sign luminaire EXIT N PU
Ex-Junction- and Terminal-Boxes		
	GHG 721 0001 R0001	Terminal box Ex-e, without drilling, 1 x 2,5 mm
	GHG 721 1001 R0003	Terminal box Ex-e, without drilling, 1 x Ex-e/24 x PE
	GHG 731 1102 R0531	Terminal box Ex-e, without drilling, 1 x Ex-e/UT 3 N/7 x PE/PA
	GHG 791 0101 R0001	Junction box Ex-e 4 x 4 mm ² + PE, 2 x M25
	GHG 791 0101 R0002	Junction box Ex-e 4 x 4 mm ² + PE, 4 x M25
	GHG 791 0101 R0003	Terminal box Ex-e 6 x 2,5 mm ² , 1 x M25/1 x M25 drilling
	GHG 791 0101 R0004	Terminal box Ex-e 6 x 2,5 mm ² , 1 x M25/1 x M25 drilling
	GHG 791 0101 R0019	Junction box Ex-e 4 x 4 mm ² + PE for metal cable gland, 4 x M20
	GHG 791 0201 R0001	Junction box Ex-e 6 x 4 mm ² + 2 PE, 6 x M25
	GHG 791 0201 R0002	Junction box Ex-e 6 x 4 mm ² + 2 PE, 6 x M32
	GHG 791 0201 R0003	Junction box Ex-e for metal cable gland, 6 x M20
	GHG 791 0201 R0006	Junction box Ex-e 6 x 4 mm ² + 2 x PE, 4 x M25
	GHG 791 0201 R0007	Junction box Ex-e 6 x 4 mm ² + 2 x PE, 4 x M32
	Ex-Safety Switches	
	GHG 273 2000 R0003	Safety switch ON-OFF switch 2-pole, 2 x M20 only drilling
	GHG 273 2000 R0017	Safety switch ON-OFF switch 2-pole, 1 x M25
	GHG 273 2000 R0018	Safety switch ON-OFF switch 2-pole, 2 x M25
	GHG 273 4000 R0004	Safety switch Taster 2-pole, 1 x M25
	GHG 273 6000 R0003	Installation switch change-over switch 2-pole 2 x M20 only drilling
	GHG 273 6000 R0011	Installation switch change-over switch 2-pole, 1 x M25
Ex-Safety and Main Current Switches		
	GHG 261 0005 R0005	Safety switch 10 A 3-pole with aux. contact 1 NO, 2 x M20
	GHG 261 0005 R0009	Safety switch 10 A 3-pole with aux. contact 1 NO, 2 x M25/1 x M20
	GHG 261 0005 R0010	Safety switch Emergency Stop 10 A 3-pole with aux. contact 1 NO, 2 x M25/1 x M20
	GHG 262 2301 R0001	Safety switch 20 A 3-pole with aux. contact 1 NO, 2 x M32/1 x M25
	GHG 262 2301 R0002	Safety switch Emergency Stop 20 A 3-pole with aux. contact 1 NO, 2 x M32/1 x M25
	GHG 262 2301 R0007	Safety switch 20 A 4-pole with aux. contact 1 NO+ 1 NC, 2 x M20
	GHG 263 2301 R0001	Safety switch 40 A 3-pole with aux. contact 1 NO, 2 x M40/1 x M25
	GHG 263 2301 R0002	Safety switch Emergency Stop 40 A 3-pole with aux. contact 1 NO, 2 x M40/1 x M25
	GHG 263 2301 R0007	Safety switch 40 A 4-pole with aux. contact 1 NO + 1 NC, 2 x M25

Quick Delivery Service

If your order is received in our customer service centre before 12.00 noon, we ensure that the goods are dispatched within three working days, without any extra charge.

For contact information: www.crouse-hinds.de

Product group	Order-No.	Description
Ex-Plugs and Sockets		
	GHG 511 3304 R0001	Coupler Zone 1; 16 A 110-130 V / 3-pole
	GHG 511 3306 R0001	Coupler Zone 1; 16 A 200-250 V / 3-pole
	GHG 511 3506 R0001	Coupler Zone 1; 16 A 200-250 V / 380-415 V / 5-pole
	GHG 511 4306 R0001	Wall socket Zone 1; 16 A 200-250 V / 3-pole
	GHG 511 4306 R0002	Wall socket Zone 1; 16 A 200-250 V / 3-pole
	GHG 511 4306 R3001	Wall socket Zone 1; 16 A 200-250 V / 3-pole / metal cable gland
	GHG 511 4406 R0001	Wall socket Zone 1; 16 A 380-415 V / 4-pole
	GHG 511 4506 R0001	Wall socket Zone 1; 16 A 200-250 V / 380-415 V / 5-pole
	GHG 511 7304 R0001	Plug Zone 1; 16 A 110-130 V / 3-pole
	GHG 511 7306 R0001	Plug Zone 1; 16 A 200-250 V / 3-pole
	GHG 511 7406 R0001	Plug Zone 1; 16 A 380-415 V / 4-pole
	GHG 511 7506 R0001	Plug Zone 1; 16 A 200-250 V / 380-415 V / 5-pole
	GHG 511 8306 R0001	Flange socket Zone 1; 16 A 200-250 V / 3-pole
	GHG 512 4406 R0001	Wall socket Zone 1; 32 A 380-415 V / 4-pole
	GHG 512 4506 R0001	Wall socket Zone 1; 32 A 200-250 V / 380-415 V / 5-pole
	GHG 512 7406 R0001	Plug Zone 1; 32 A 380-415 V / 4-pole
	GHG 512 7407 R0001	Plug Zone 1; 32 A 480-500 V / 4-pole
	GHG 512 7506 R0001	Plug Zone 1; 32 A 200-250 V / 380-415 V / 5-pole
	GHG 514 7407 R0001	Plug Zone 1; 63 A 480-500 V / 4-pole
	GHG 514 7506 R0001	Plug Zone 1; 63 A 200-250 V / 380-415 V / 5-pole
GHG 610 1953 R0104	Mounting plate size 2 for wall mounting	
Ex-Control Units for Panel Mounting		
	GHG 410 1901 R0125	Locking facility with flap (red) for mushroom-head pushbutton
	GHG 410 1901 R0126	Locking facility with hammer
	GHG 410 1953 R0001	Label with holder
	GHG 410 1901 R0295	Lamp socket 20-250 V AC/DC
	GHG 418 8170 R 0053	Signal lamp ER 12-24 V AC/DC
	GHG 418 8170 R0051	Signal lamp 20-250 V AC/DC LED for panel mounting (various colours)
	GHG 418 8115 R0001	Pushbutton 1 NO + 1 NC / „0-I-Stop-Start“ for panel mounting
	GHG 418 8153 R1200	Mushroom-head pushbutton Emergency Stop / NO, 2 NC, red, German , English, for panel mounting
	GHG 418 8155 R1200	Mushroom-head pushbutton Emergency Stop / 1 NO + 1 NC for panel mounting
	GHG 610 1953 R0101	Mounting plate Size 1
	GHG 610 1953 R0102	Mounting plate Size 1 for pipe mounting
	GHG 610 1953 R0105	Mounting plate Size 2 for pipe mounting
	GHG 610 1953 R0110	Mounting plate Size 3 for pipe mounting
	GHG 610 1955 R0102	Canopy for mounting plate size 2
Ex-Control Units and Control Stations		
	GHG 411 8100 R0001	Control unit, pushbutton 1 NO + 1 NC, 1 x M25
	GHG 411 8100 R0002	Control unit, Emergency Stop 1 NO+ 1 NC, 1 x M25
	GHG 411 8101 R0093	Control unit, Emergency Stop NO, unlock by pulling, 2 NC, 1 x M25
	GHG 411 8101 R1826	Control unit, Emergency Stop NO, 1 x M20
	GHG 411 8200 R0001	Control unit, 2 x pushbutton 1 NO+ 1 NC, 1 x M25

Detailed specification documents of our products are available in our master catalogue or on our website: <https://www.crouse-hinds.de/en/products>

If your order is received in our customer service centre before 12.00 noon, we ensure that the goods are dispatched within three working days, without any extra charge.

For contact information: www.crouse-hinds.de

Product group	Order-No.	Description	
Ex-Cable Glands			
	GHG 960 1927 R0105	Ex-e plastic drainage plug M25 x 1.5	
	GHG 960 1944 R0103	Ex-e plastic blanking plug M20 x 1.5	
	GHG 960 1944 R0104	Ex-e plastic blanking plug M25 x 1.5	
	GHG 960 1949 R0112	Ex-e plastic trumped shaped gland M25 x 1.5	
	GHG 960 1952 R0111	Ex-e plastic screw plug M16 x 1.5	
	GHG 960 1952 R0112	Ex-e plastic screw plug M20 x 1.5	
	GHG 960 1952 R0113	Ex-e plastic screw plug M25 x 1.5	
	GHG 960 1952 R0114	Ex-e plastic screw plug M32 x 1.5	
	GHG 960 1952 R0115	Ex-e plastic screw plug M40 x 1.5	
	GHG 960 1952 R0116	Ex-e plastic screw plug M50 x 1.5	
		GHG 960 1954 R0002	Ex-e plastic breathing and drainage plug M25 x 1.5
		GHG 960 1955 R0001	Ex-e plastic cable gland M12 x 1.5, short thread
GHG 960 1955 R0002		Ex-e plastic cable gland M16 x 1.5, short thread	
GHG 960 1955 R0003		Ex-e plastic cable gland M20 x 1.5, short thread	
GHG 960 1955 R0004		Ex-e plastic cable gland M25 x 1.5, short thread	
	GHG 960 1955 R0005	Ex-e plastic cable gland M32 x 1.5, short thread	
	GHG 960 1955 R0022	Ex-e plastic cable gland M16 x 1.5, long thread	
	GHG 960 1955 R0023	Ex-e plastic cable gland M20 x 1.5, long thread	
	GHG 960 1955 R0024	Ex-e plastic cable gland M25 x 1.5, long thread	
	GHG 960 1955 R0025	Ex-e plastic cable gland M32 x 1.5, long thread	
	GHG 960 1955 R0026	Ex-e plastic cable gland M40 x 1.5, long thread	
	GHG 960 1955 R0027	Ex-e plastic cable gland M50 x 1.5, long thread	
		GHG 960 1955 R0102	Ex-i plastic cable gland M16 x 1.5, short thread
		GHG 960 1955 R0103	Ex-i plastic cable gland M20 x 1.5, short thread
		GHG 960 1955 R0104	Ex-i plastic cable gland M25 x 1.5, short thread
GHG 960 1955 R0123		Ex-i plastic cable gland M20 x 1.5, long thread	
	GHG 960 1955 R0124	Ex-i plastic cable gland M25 x 1.5, long thread	
	GHG 960 1956 R0003	Ex-e plastic thread enlargement M20/M25	
	GHG 960 1956 R0004	Ex-e plastic thread enlargement M25/M32	
	CAP 806505 V1	Ex-de metal cable gland M16	
	CAP 806605 V1	Ex-de metal cable gland M20	



Eaton's Crouse-Hinds Business

The safety you rely on.

See the complete offering of Hazardous and Industrial Products at www.crouse-hinds.de.

**U.S. (Global Headquarters):
Eaton's Crouse-Hinds
Business**

1201 Wolf Street
Syracuse, NY 13208

(866) 764-5454
FAX: (315) 477-5179
FAX Orders Only:
(866) 653-0640

CrouseCustomerCTR@Eaton.com

For more information:

If further assistance is required, please contact an authorized Eaton Distributor, Sales Office, or Customer Service Department.

Australia

Phone +61-2-8787-2777
Fax +61-2-9609-2342
crousehindsanz@eaton.com

China

Phone +86-21-2899-3600
Fax +86-21-2899-4055
ECHsales@eaton.com

Great Britain

Phone +44-247-630-89 30
Fax +44-247-630-10 27
sales5@eaton.com

India

Phone +91-124-4683888
Fax +91-124-4683899
cchindia@eaton.com

Canada

Toll Free +1-800-265-0502
Fax +1-800-263-9504
Fax orders only:
+1-866-653-0645

Korea

Phone +82-2-3484-6783
Fax +82-2-3484-6778
CCHK-sales@eaton.com

**Mexico/Latin America/
Caribbean**

Phone +52-555-804-4000
Fax +52-555-804-4020
ventascentromex@eaton.com

Spain

Phone +34-9-37362710
Fax +34-9-37835055
sales.CCH.es@cooperindustries.com

Middle East (Dubai)

Phone +971-4-427-2522 / 2500
Fax +971-4-429-8521
CHMEsales@eaton.com

The Netherlands

Phone +31-10-2452145
Fax +31-10-2452121
CHRD_mail@eaton.com

Norway

Phone +47-32-244600
Fax +47-32-244646
CHLloffice@eaton.com

Singapore:

Phone +65-6645-9888
Fax +65-6297-4819
CHSI-Sales@eaton.com

Turkey

Phone +90-216-464-20-20
Fax +90-216-464-20-10
infoEGTurkey@eaton.com

Russia

Phone +7-495 510-24-27
Fax +7-495 510-24-28
info@cooper.ru.com
www.cooper-russia.ru

Eaton's Crouse-Hinds Business

Neuer Weg – Nord 49
D-69412 Eberbach

Phone +49 (0) 6271/806-500
Fax +49 (0) 6271/806-476
E-mail info-ex@eaton.com
Internet www.crouse-hinds.de

Eaton

1000 Eaton Boulevard
Cleveland, OH 44122
United States
Eaton.com

© 2015 Eaton Corporation
All Rights Reserved
Printed in Germany
Publication No. BR ####
May 2015

Changes to the products, to the information contained in this document, and to prices are reserved; so are errors and omissions. Only order confirmations and technical documentation by Eaton is binding. Photos and pictures also do not warrant a specific layout or functionality. Their use in whatever form is subject to prior approval by Eaton. The same applies to Trademarks (especially Eaton, Moeller, and Cutler-Hammer). The Terms and Conditions of Eaton apply, as referenced on Eaton Internet pages and Eaton order confirmations.

Eaton's Crouse-Hinds Business

1201 Wolf Street
Syracuse, NY 13208
(866) 764-5454
CrouseCustomerCTR@Eaton.com

Eaton is a registered trademark.

All other trademarks are property of their respective owners.