

Pitch: .100"

MODULAR, .025" SQUARE SYSTEM STRIP HEADER

SPECIFICATIONS

ENVIRONMENTAL

Temperature Range: -55°C to +105°C

MECHANICAL

Insulator Material: Glass-filled polyester, black, UL94V-0

Contact Material: Phosphor Bronze

Contact Plating: See options below


ELECTRICAL

Current Rating: 1 AMP

CA- SERIES POSITION -24 PLATING -44

Consult factory for additional pin length options

SERIES	POSITION	PLATING
S = Single Row	Single 01 thru 36	B = 10μ gold
D = Dual Row	Dual 04 thru 72	C = 15μ sel gold
T = Triple Row	Triple 09 thru 108	T = 150μ IN 90/10 tin/lead

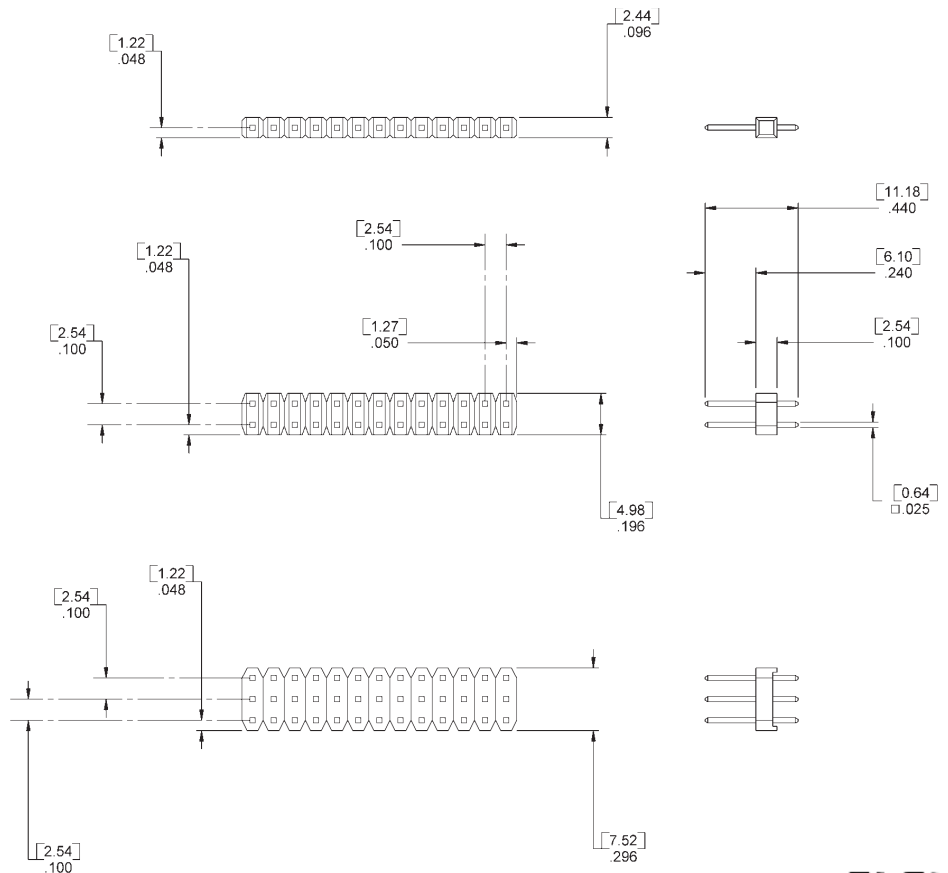

Mating Product: IDS2, FID, SJ, VSC
 Drawing Number CA-620389

