


For technical assistance call: 323-465-2131

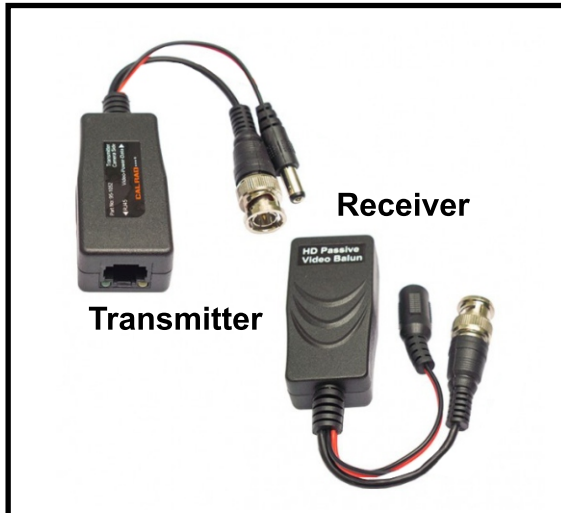

95-1053

CCTV Single Channel HD Passive Video Balun with Power

Description

Video, Power Balun with 1 x Transmitter and 1 x Receiver that allows the transmission of real - time CCTV HD power, video signal via cost - effective Unshielded Twisted Paired (UTP) cable. Baseband (composite) signals of any type are supported. The **95-1053** is compatible with all HD - TVI, HD - CVI and AHD analog cameras. Used in pairs, the **95-1053** eliminates costly and bulky coaxial cable. The superior interference rejection and low emissions of the **95-1053** allow video signals to coexist in the same wire bundle as telephone, datacom, or low - voltage power circuits, providing access to shared or pre-existing cables. The **95-1053** has a built - in surge suppressor to protect video equipment against damaging voltage spikes. The built-in circuitry provides against crosstalk and noise immunity to ensure the highest quality video signals, (Sold in Pairs).

Typical Hookup

● TVI ● CVI ● Analog HD

HD-CVI 720P 1443 ft. HD-CVI 1080P 787 ft.
HD-TVI 720P 754 ft. HD-TVI 1080P 820 ft.

HD Camera



Power
Video

95-1053 Transmitter

95-1053 Receiver

UTP Cat5e, Cat6 Cable

Power
Video

HD DVR



Specifications

UTP Termination: RJ45 Jack (8 Pin)

Cables: (Transmitter) Male BNC Plug and 2.1mm Coax Power Plug pigtail, length 5.9", **(Receiver)** Male BNC Plug and 2.1mm Coax Power Jack pigtail, length 5.9"

Video Termination: 75 Ohm Male BNC connector

Video Formats: HD-TVI, HD-CVI, AHD-Analog Signals

Video Standards: NTSC, PAL & SECAM

Signal Isolation: 60db Crosstalk and noise immunity

Power: 12-24Vdc

Lightning Protection: Design Grade III

Built-in TVS: (Transient Voltage Suppressor) for electrical surge protection

Housing: ABS Plastic

Size: Balun Body, L-2.37" x W-1.14" x H-.8"

Cable Distance:

HD-TVI 720P analog camera: Color video max up to 230m (754ft.)

HD-TVI 1080P analog camera: Color video max up to 250m (820ft.)

AHD 720P analog camera: Color video max up to 320m (1050ft.)

AHD 960P analog camera: Color video max up to 330m (1082ft.)

HD-CVI 720P analog camera: Color video max up to 440m (1443 ft.)

HD-CVI 1080P analog camera: Color video max up to 240m (787ft.)


Color: Black



Lightning
Protection
Circuitry

Warning!

This device is not waterproof and is not to be used outdoors unless sealed in a weatherproof housing.

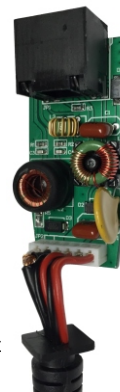

● 12-24Vdc Power

● Built-In TVS for Surge Protection

● Built-in surge protection

Video Power

