

SHOP BY CATEGORY

All Categories SEARCH

All Products [Home](#) > [All Products](#) > [92 Series- L.E.D.'s & L.E.D. holders](#) > RGB Controller with IR Remote

3D Products **Model: 92-348 | RGB Controller with IR Remote**

New Products

Spec Sheets

Personal Info

Click To View
OUR LATEST CATALOG 61



RGB Controller with IR Remote

Item# 92-348



Product Description

92-348 | RGB Controller with IR Remote, 144 Watts. The L.E.D. RGB controller provide 12Amps, 144 watts of current to drive RGB based L.E.D. lighting strips. Works with all Calrad RGB L.E.D. lighting. Dual power options, DC coax jack (5A), terminal block (12A). Non volatile memory retains last settings when DC power is removed or lost.

Typical Hookup




Specifications:

- Voltage: 12-24Vdc
- IR Frequency: 38Khz
- Discrete IR Power On/Off
- Output Current Total: 12 Amps
- Output Current Red: 4 Amps
- Output Current Green: 4 Amps
- Output Current Blue: 4 Amps
- Connecting Mode: Common Anode (V+)
- IR Remote Battery: 3V CR2025L
- Connectors: 2.1mm Coax power jack (5Amps) Secondary Power, Removable 6 position phoenix jack (DC Power 12Amps Primary Power + RGB, V+), accepts up to 14Awg. cable.
- Remote Size: L - 3.3Åçâ, -Å¥ x W - 2Åçâ, -Å¥ x Thickness - .28Åçâ, -Å¥
- Chassis Size: L - 4.05Åçâ, -Å¥ x W - 2.5Åçâ, -Å¥ x H - .93Åçâ, -Å¥, Material: Aluminum
- Mounting Tabs: (Two) L - 1.15Åçâ, -Å¥ x W - .54Åçâ, -Å¥ x Thickness .06Åçâ, -Å¥, .6Åçâ, -Å¥ x .15Åçâ, -Å¥ mounting slot



The Do's and Dont's of wiring multiple L.E.D. Strips

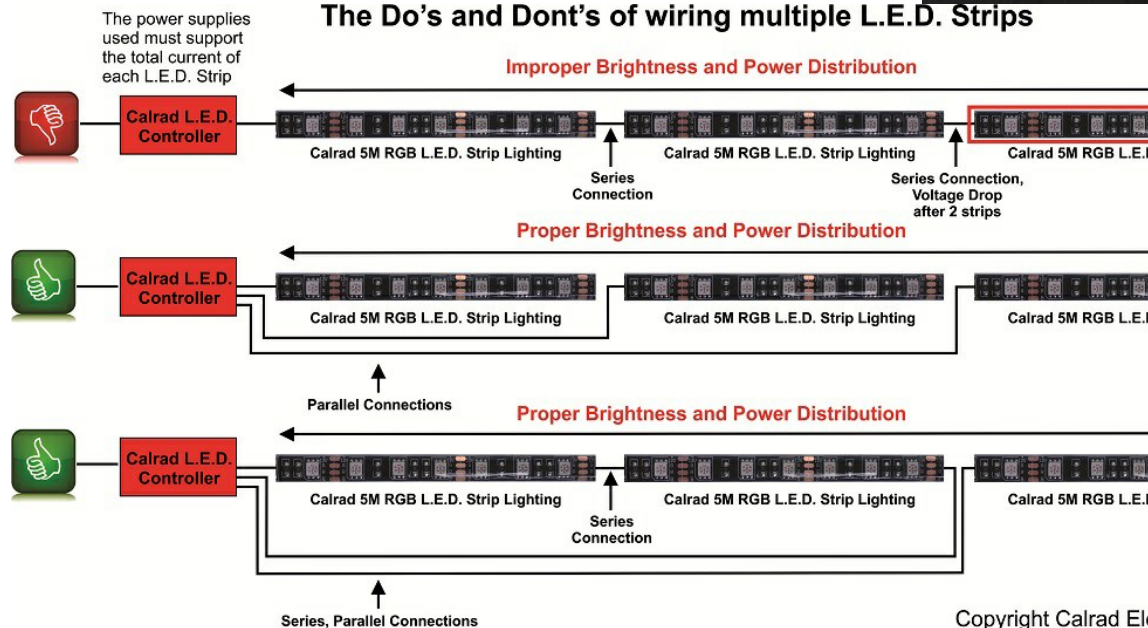

Delete Credit/Debit Card

Are you sure you want to delete this card from your saved cards?