


2120A and 2121A Series Non-Relampable Neon Lights

Description and Features

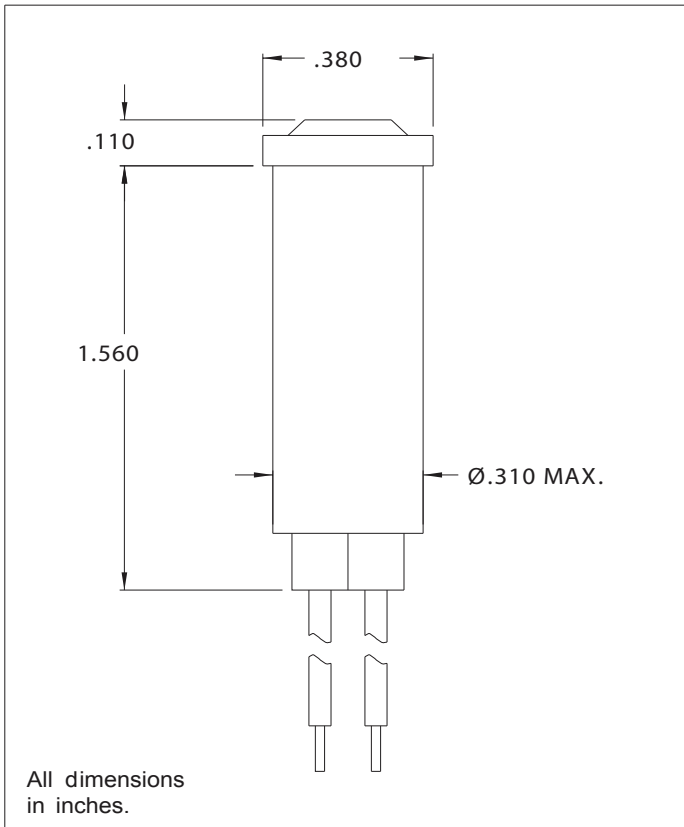

Mounting: Ø.310 MIN., supplied with push-on speednut SN1287.

Wire Leads: No. 22 AWG (105°C), 4.40/4.80 long, stripped .430/.570.

Lens: Polycarbonate

Bezel: White nylon. For black finish add "X" after the series letter(s).

Housing: White Nylon

Lens Color	Neon	
	Model No. (105-125VAC)	Model No. (208-250VAC)
Red	2120A1	2121A1
Amber	2120A3	2121A3
White	2120A4	2121A4
Lamp used	C2A+Resistor	C2A+Resistor

Underwriters Laboratories (UL) File No. E20325
Canadian Standards Association (CSA) File No. LR13346