

REV. 1 1/25/94


COIL: @ +25 °C
 RESISTANCE 700 OHMS ± 10%
 NOMINAL VOLTAGE 20.0-30.0 VDC
 MUST OPERATE 13.5 VDC
 MUST RELEASE 8.0 VDC MAX, 1.5 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 11 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE TIME 4 MS MAX
CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

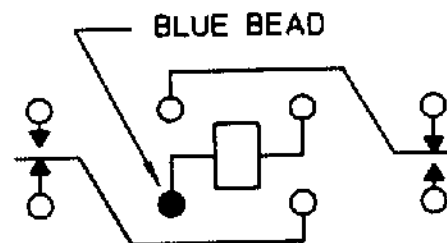

CONTACT RATING: LOW LEVEL TO 2 AMPS
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 6/3/92 CK. 1/25/94

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. GENICOM
 CUST. NO. 3SAV5002H1

TYPE "HFW" RELAY

HFW1101K13