


REV. 0  
DCO 17597

COIL: @ 25°C	
RESISTANCE	675 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.0 VDC
MUST RELEASE	1.5 VDC

ENVIRONMENT:	
VIBRATION	10 Hz TO 2000 Hz @ 20 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE 6 MS MAX  
RELEASE 3 MS MAX  
CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

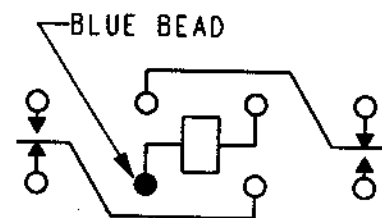

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO  
5 AMPS 30 VDC RESISTIVE, 2 AMPS 115  
VAC 60 HZ RESISTIVE 100,000 OPERATIONS

DR. ASB 17 MAY 02 CK 5/26/02

**CII Technologies**  
advanced control electronic solutions

CUST. HI-G  
CUST. NO. 28N-1E-126 REV.

"FW5A" RELAY

FW5A1196S02