


COIL: @ 25° C	
RESISTANCE	160 OHMS ± 10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	6.5 VDC
MUST RELEASE	.75 VDC

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 20 g's
SHOCK	100 g's 6 ± 1 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE 4 MS MAX.
RELEASE 2 MS MAX.
CONTACT BOUNCE 3 MS MAX.

CUSTOMER DATA SHEET

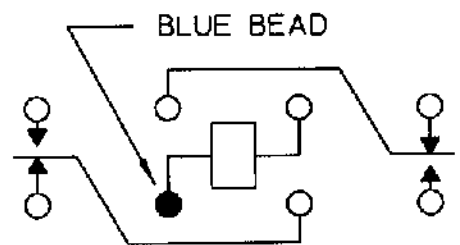

CONTACT RATING: 2 AMPS 30 VDC
RESISTIVE .75 AMP 30 VDC INDUCTIVE
100,000 OPERATIONS

DR. R.B. 10/20/95 CK. 10/20/95

COMMUNICATIONS INSTRUMENTS, INC.

CUST. HI-G
CUST. NO. 2K-1B-112

TYPE 'HFW' RELAY

HFW1196S02