


REV. 0

DCO 16677

COIL: @ 25°C	
RESISTANCE	1250 OHMS ±10%
NOMINAL VOLTAGE	26.5 - 32 VDC
MUST OPERATE	14.0 VDC
MUST RELEASE	1.5 VDC

ENVIRONMENT:	
VIBRATION	20 CPS TO 2000 CPS @ 20 g's
SHOCK	100 g's 6 ±1 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES: OPERATE & RELEASE 4 MS MAX.	
CONTACT BOUNCE 2.0 MS MAX.	

CUSTOMER DATA SHEET

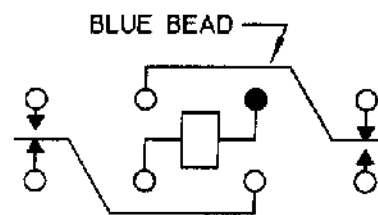

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 4A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 12/15/00 CK. TLG 12-15-00

CII Technologies
advanced control electronic solutions

CUST. C.I. CATALOG
CUST. NO. REV.
"HFW4A" RELAY

HFW4A1231D00