


FCA - 210 - 0923M Product Details

[Share](#)
[Print](#)
[Email](#)

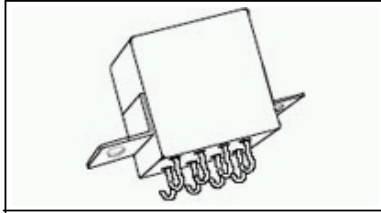

FCA - 210 - 0923M
 (9 - 1617748 - 8)

TE Internal Number: 9 - 1617748 - 8

 [Active](#)

Military/Aerospace Mid - Range Relays

[Not EU RoHS or ELV Compliant](#)

Product Highlights:

- ? FCA 10 - 25 Amp Relay Series
- ? DC Actuating System
- ? Coil - Rated Voltage = 28 VDC
- ? Coil Resistance = 320 ?
- ? Contact Arrangement = 2 Form C, DPDT, 2 C/O

[View all Features](#)

Quick Links

- ? [Check Pricing & Availability](#)
- ? [Search for Tooling](#)
- ? [Product Feature Selector](#)
- ? [Contact Us About This Product](#)

[Add to My Part List](#)
[Request Sample](#)
[Find Similar Products](#)
[Buy Product](#)

Documentation & Additional Information

Product Drawings:

- ? [MSD RELAY](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? Series = FCA 10 - 25 Amp Relay
- ? [Terminal Configuration](#) = Solder Hook

Electrical Characteristics:

- ? [Actuating System](#) = DC
- ? [Coil - Rated Voltage \(VDC\)](#) = 28
- ? Coil Resistance (?) = 320
- ? [Current Rating \(A\)](#) = 10
- ? Shock = 200G's, 6ms
- ? Vibration = 30G's, 33 to 3000Hz

Termination Features:

- ? [Terminal Plating](#) = Tin -Lead
- ? Auxiliary Contacts = Without

Body Features:

- ? Mount Type = Raised Vertical Flange Mount

Contact Features:

- ? Enclosure Type = Hermetically Sealed

Configuration Features:

- ? [Contact Arrangement](#) = 2 Form C, DPDT, 2 C/O
- ? [Coil Suppression Diode](#) = Without
- ? Coil - Magnetic System = Polarized, Monostable

Industry Standards:

- ? Government/Industry Qualification = Yes
- ? Government/Industry Part Number = M83536/9 -023M
- ? [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- ? [Lead Free Solder Processes](#) = Not suitable for lead free processing

Other:

- ? Brand = CII

Corporate Information

- [Who We Are](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

