
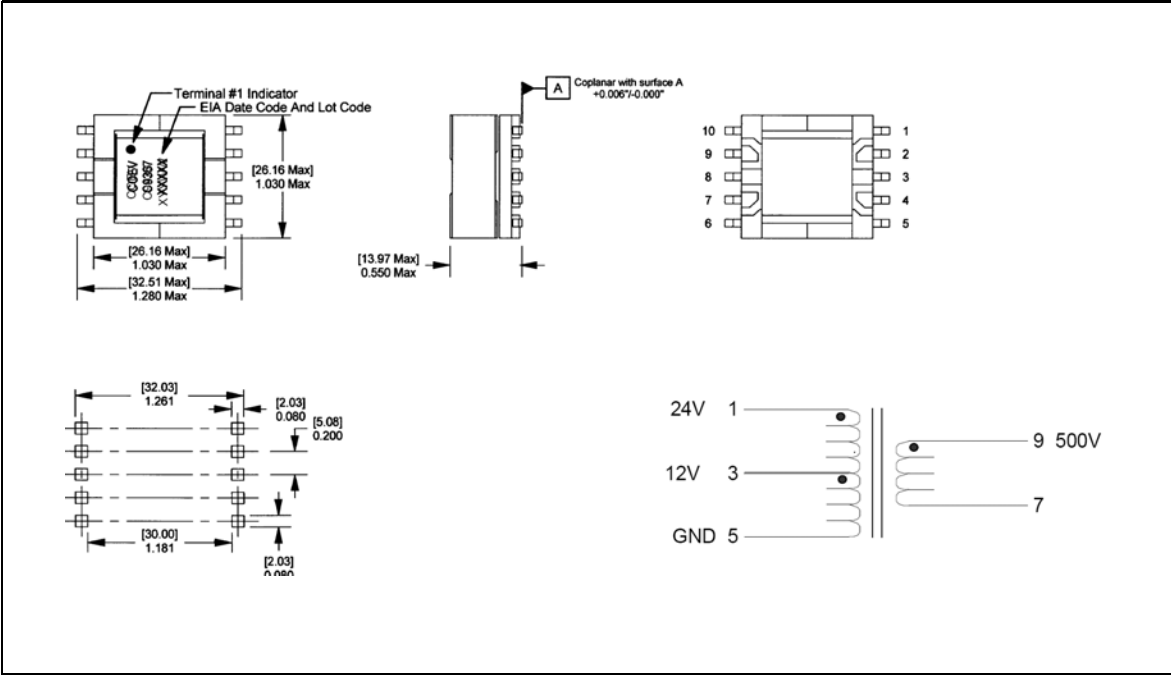
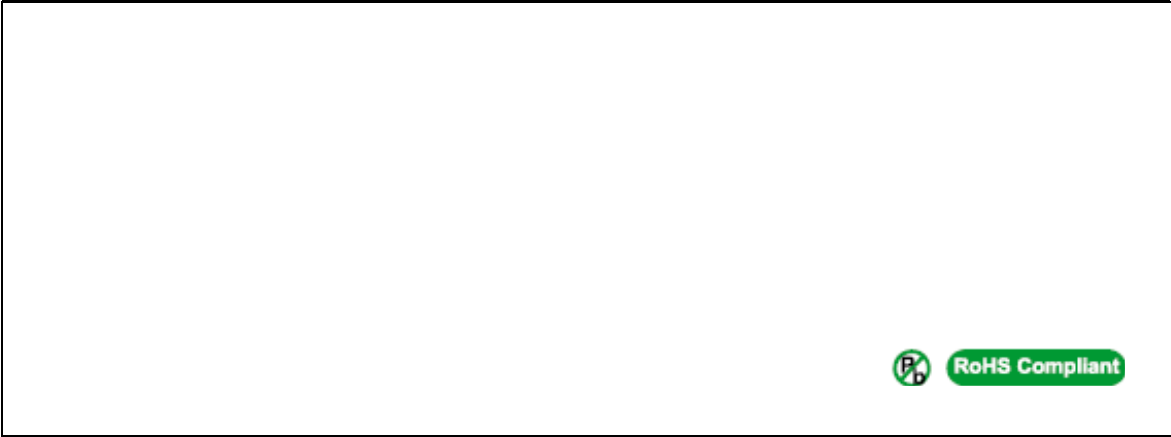


C9423-P	REV	
1879395-1	BA	
Product Description	XFMR PROP EFD25 SMD GW RoHS Version C9423	



Information subject to change without notice Primary Units in Inches Millimetres in brackets

Electrical Specifications at +20°C unless noted otherwise				
Test Description	Limit	Units	Tol	Notes
Inductance	22.00	μH	±5%	1-5, 10kHz, 100mVAC, Ls.
DC Resistance	0.040	Ω	Max.	1 - 3
DC Resistance	0.040	Ω	Max.	3 - 5
DC Resistance	16.50	Ω	Max.	9 - 7
Turns Ratio	1.222 : 1	--	±2%	(1-3) : (3-5), 10KHz, 100mVAC.
Turns Ratio	0.044 : 1	--	±2%	(1-5) : (8-6), 10KHz, 100mVAC.
Dialectric	1,000	VAC	500μA	1-9, 1 second test, 500μA maximum leakage current.



The information contained in this drawing is the sole property of Tyco Electronics. Any reproduction or use without the written permission of Tyco Electronics is prohibited.

Specifications subject to change without notice. For latest revision visit <http://www.tycoelectronics.com>