



PRODUCTS & SERVICES:

Switches >

Indicator Lights >

Connectors >

Defense/Aerospace
Connectors >

Contract
Manufacturing >

Custom Assembly >

Custom Switches and
Connectors >



Search Catalog

By Keyword


All Categories Socket Connectors

[All Categories](#) > [Connectors](#) > [Insulation Displacement Connectors - Commercial & MIL SPEC](#) > [Insulation Displacement Connectors - Commercial](#) > [Socket Connectors](#) > Item # CWR-220-26-0203

[Download PDF](#) [Printable Page](#) [Email This Page](#) [Save To Favorites](#)

Request Information

Item # CWR-220-26-0203, Socket Connectors

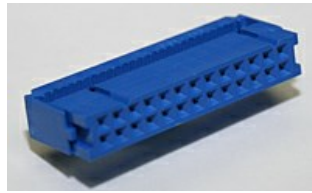

larger image

[Check Distributor Stock](#) · [Specifications](#)

Check Distributor Stock

Check Distributor Stock [DIGI-KEY](#) [MOUSER](#)

Specifications

| | |
|--|--|
| Style | IDC |
| Connector Type | Socket |
| Mounting | Without Strain Relief |
| Plating | Tin |
| Polarization | Polarization Slots |
| Number of Contacts | 26 |
| Contacts | Phosphor Bronze Standard |
| Insulator Material | UL 94V-0 Flame Retardant Thermoplastic |
| Strain Relief Strap Material | Insulated Stainless Steel |
| Color | Blue |
| Operating Temperature | -55 to +125 °C |
| Maximum Current Rating (Per Contact) | 1 A |
| Dielectric Withstand Voltage | Greater Than 500 VDC at Sea Level |
| Insulation Resistance | Greater Than 5 x 10 ⁹ ohms |
| Typical Withdrawal Force | 2-8 oz/contact |
| Minimum Cover Pull-Off Force (Force Along Contacts Primary Axes) | 8 oz/contact |
| Compliance | |

Request Information

MORE IMAGES

- Features of Socket Connectors
- Socket Connectors with Metal Strain Relief Strap
- Socket Connectors with Non-Strain Relief Cover
- Contact Drawing for Socket Connectors
- Polarization Drawing of Socket Connectors
- Polarization Method Drawing of Socket Connectors
- How to Order Socket Cable Assemblies

DOWNLOADS

Dim Dwg CWR-220-XX-0203 (PDF, 513KB)

Plastic Key for Socket Connectors



[Plastic Key for Socket Connector](#)