



BALL KNOBS


**BLACK**

proceed to red ball knobs >>



**Material- Phenolic**  
**Insert- Brass**  
 † Insert- Steel, zinc plated



Molded Thread

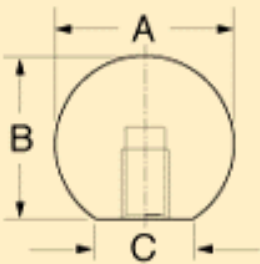

Threaded Insert

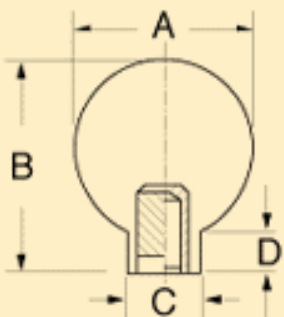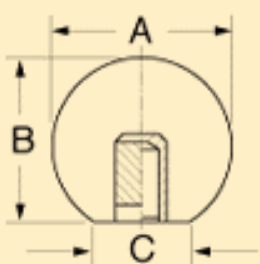

Threaded Insert w/Shank

**Threaded Insert**

Part No.	Insert	
	Thread	Depth
<a href="#">0025-Q</a>	1/4-20	3/8
<a href="#">0025AN</a> *4	1/4-20	3/8
<a href="#">0025AU</a>	5/16-18	1/2
<a href="#">0025BW</a> *4	5/16-18	1/2

\*w/shank 4" B"=1-1/2, "D"=5/16

3" B"=27/32, "D"=1/4, 5" B"=1-13/16, "D"=1/2

**Molded Thread**

Part No.	Thread	Depth
<a href="#">0025BY</a>	3/8-16	5/8
<a href="#">0025</a>	1/4-20	5/8

\*w/shank

1" B"=1-1/2, "D"=5/16

2" B"=1-13/16, "D"=1/2

[← back](#)