


« Clamping Knobs

## Knurled Scalloped Clamping Knobs

### Series #3055

- ▶ Clamping knobs are available in different materials, thermoplastic, and phenolic for a multiple of applications.
- ▶ A variety of shapes and diameters with plain, tapped bosses or with studs are available with standard threads to fit the application.
- ▶ Perfect for the industrial machinery, medical, general equipment and other industrial applications.
- ▶ Knobs can be decorated or customized to your specific need.
- ▶ Davies Molding is pleased to introduce our series of soft touch knobs and handles. Our soft touch parts are molded with a soft thermoplastic overmolded "rubber" top with a tough thermoplastic body underneath. The soft feel of the knob provides a comfortable touch with a sure grip.
- ▶ Colors available upon request.
- ▶ Please note: Not all variations available are listed below. Please [contact customer service](#) to inquire about all available options.

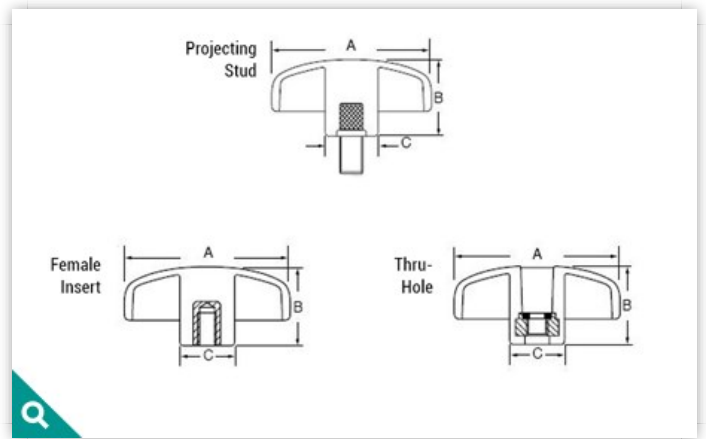

CHECK INVENTORY

REQUEST A QUOTE

Item #	Diameter A	Height B	Hub C	Material Type	Mounting Diameter	Mounting Type	Thread Length/Depth	Color	Product Drawing
3055	1.25	0.75	0.75	Thermoset	1/4-20	Female Insert	0.375	Black	<a href="#">Download</a>
3055-A	1.25	0.75	0.75	Thermoset	5/16-18	Female Insert	0.50	Black	<a href="#">Download</a>
3055-B	1.25	0.75	0.75	Thermoset	3/8-16	Female Insert	0.50	Black	<a href="#">Download</a>
3055-C	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	0.56	Black	<a href="#">Download</a>
3055-D	1.25	0.75	0.75	Thermoset	5/16-18	Projecting Stud	0.75	Black	<a href="#">Download</a>
3055-E	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	1.875	Black	<a href="#">Download</a>
3055-F	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	0.625	Black	<a href="#">Download</a>
3055-G	1.25	0.75	0.75	Thermoset	3/8-16	Projecting Stud	0.75	Black	<a href="#">Download</a>
3055-K	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	1.25	Black	<a href="#">Download</a>
3055-N	1.25	0.75	0.75	Thermoset	10-24	Female Insert	0.375	Black	<a href="#">Download</a>
3055-Q	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	0.875	Black	<a href="#">Download</a>
3055-S	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	0.75	Black	<a href="#">Download</a>
3055-Y	1.25	0.75	0.75	Thermoset	3/8-16	Projecting Stud	1.00	Black	<a href="#">Download</a>
3055-Z	1.25	0.75	0.75	Thermoset	3/8-24	Female Insert	0.50	Black	<a href="#">Download</a>
3055AE	1.25	0.75	0.75	Thermoset	5/16-18	Projecting Stud	0.50	Black	<a href="#">Download</a>
3055AG	1.25	0.75	0.75	Thermoset	0.25	Bushing	0.47	Black	<a href="#">Download</a>

3055AL	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	1.00	Black	<a href="#">Download</a>
3055AP	1.25	0.75	0.75	Thermoset	10-32	Female Insert	0.375	Black	<a href="#">Download</a>
3055AS	1.25	0.75	0.75	Thermoset	5/16-18	Projecting Stud	2.50	Black	<a href="#">Download</a>
3055AT	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	0.375	Black	<a href="#">Download</a>
3055AV	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	1.50	Black	<a href="#">Download</a>
3055AY	1.25	0.75	0.75	Thermoset	0.25	Plain Molded Hole	0.50	Black	<a href="#">Download</a>
3055BA	1.25	0.75	0.75	Thermoset	5/16-18	Female Insert	0.50	Black	<a href="#">Download</a>
3055BD	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	2.50	Black	<a href="#">Download</a>
3055BF	1.25	0.75	0.75	Thermoset	5/16-24	Female Insert	0.50	Black	<a href="#">Download</a>
3055BK	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	0.50	Black	<a href="#">Download</a>
3055BL	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud SS	0.75	Black	
3055BS	1.25	0.75	0.75	Thermoset	0.25	Plain Molded Hole	0.50	Black	<a href="#">Download</a>
3055BX	1.25	0.75	0.75	Thermoset	1/4-20	Female Insert	0.375	Black	<a href="#">Download</a>
3055CR	1.25	0.75	0.75	Thermoset	3/8-16	Projecting Stud	1.50	Black	<a href="#">Download</a>
3055CX	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	0.375	Red	<a href="#">Download</a>
3055NP	1.25	0.75	0.75	Thermoset	10-32	Projecting Stud	0.75	Black	<a href="#">Download</a>
3055NV	1.25	0.75	0.75	Thermoset	1/4-20	Projecting Stud	1.75	Black	<a href="#">Download</a>
3055NZ	1.25	0.75	0.75	Thermoset	3/8-24	Projecting Stud	1.25	Black	<a href="#">Download</a>
3055PA	1.25	0.75	0.75	Thermoset	3/8-16	Projecting Stud	0.75	Red	<a href="#">Download</a>
3055PB	1.25	0.75	0.75	Thermoset	1/4-28	Thru-Hole		Black	<a href="#">Download</a>
3055PC	1.25	0.75	0.75	Thermoset	1/4-28	Thru-Hole		White	<a href="#">Download</a>
3055PF	1.25	0.75	0.75	Thermoset	10-32	Projecting Stud SS	1.00	Black	
3055PH	1.25	0.75	0.75	Thermoset	5/16-18	Projecting Stud SS	1.00	Black	

PRODUCTS

- [Knobs](#)
- [Handles](#)
- [Electronic Enclosures](#)
- [Hex Hybrid Standoffs](#)
- [Two-Shot / Soft Touch](#)
- [Frac Balls](#)
- [Cable Glands](#)
- [Rubber Grommets](#)
- [Custom Molding](#)

RESOURCES

- [Engineering Specifications](#)
- [Distributor Listing](#)
- [Sales Representative Listing](#)

COMPANY

- [About Us](#)
- [Capabilities](#)
- [Certifications](#)
- [Contact Us](#)
- [Blog](#)
- [Careers](#)

QUESTIONS ?

questions / comments

1 + 1 =  \*

**SEND**