


« Clamping Knobs

Round Fluted Clamping Knobs

Series #2965

- ▶ Clamping knobs are available in different materials, thermoplastic, and phenolic for a multiple of applications.
- ▶ A variety of shapes and diameters with plain, tapped bosses or with studs are available with standard threads to fit the application.
- ▶ Perfect for the industrial machinery, medical, general equipment and other industrial applications.
- ▶ Knobs can be decorated or customized to your specific need.
- ▶ Davies Molding is pleased to introduce our series of soft touch knobs and handles. Our soft touch parts are molded with a soft thermoplastic overmolded "rubber" top with a tough thermoplastic body underneath. The soft feel of the knob provides a comfortable touch with a sure grip.
- ▶ Colors available upon request.
- ▶ Please note: Not all variations available are listed below. Please [contact customer service](#) to inquire about all available options.

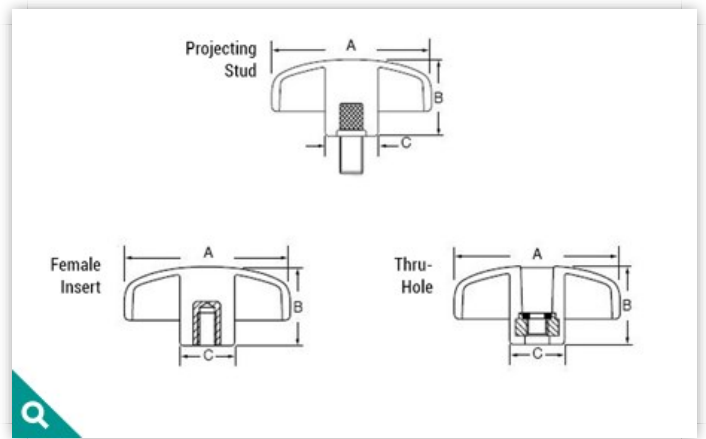

CHECK INVENTORY

REQUEST A QUOTE

Item #	Diameter A	Height B	Hub C	Material Type	Mounting Diameter	Mounting Type	Thread Length/Depth	Color	Product Drawing
2965	0.88	0.5	0.625	Thermoset	0.25	Plain Molded Hole	0.44	Black	Download
2965-H	0.88	0.5	0.625	Thermoset	8-32	Female Insert	0.25	Black	Download
2965BW	0.88	0.5	0.625	Thermoset	10-32	Female Insert	0.31	Black	Download
2965DC	0.88	0.75	0.625	Thermoset	10-32	Projecting Stud	0.625	Black	Download
2965DJ	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.44	Black	Download
2965DY	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.625	Black	Download
2965ED	0.88	0.95	0.625	Thermoset	10-32	Female Insert	0.375	Black	Download
2965EG	0.88	0.57	0.625	Thermoset	1/4-20	Projecting Stud	0.75	Black	Download
2965EN	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	1.00	Green	Download
2965EQ	0.88	0.75	0.625	Thermoset	10-32	Projecting Stud	0.75	Black	Download
2965EX	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	0.375	Black	Download
2965FA	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	1.25	Black	Download
2965FB	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	1.75	Black	Download
2965FC	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.375	Black	Download
2965FF	0.88	0.5	0.625	Thermoset	10-24	Projecting Stud	0.31	Black	Download
2965FH	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.50	Black	Download

2965FJ	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.56	Black	Download
2965FP	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.31	Black	Download
2965FY	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.875	Black	Download
2965FZ	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.31	Black	Download
2965GA	0.88	0.5	0.625	Thermoset	1/4-28	Projecting Stud	0.94	Black	Download
2965GM	0.88	0.5	0.625	Thermoset	10-24	Projecting Stud	0.375	Black	Download
2965GQ	0.88	0.5	0.625	Thermoset	10-24	Projecting Stud	0.50	Black	Download
2965GS	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	1.25	Black	Download
2965GZ	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	1.00	Black	Download
2965HG	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.625	Black	Download
2965HH	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	1.125	Black	Download
2965HJ	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	0.50	Black	Download
2965HR	0.88	0.94	0.625	Thermoset	1/4-20	Projecting Stud	0.50	Black	Download
2965HW	0.88	0.625	0.625	Thermoset	1/4-20	Female Insert	0.375	Black	Download
2965JA	0.88	0.94	0.625	Thermoset	1/4-20	Female Insert	0.375	Black	Download
2965JB	0.88	0.75	0.625	Thermoset	1/4-20	Female Insert	0.375	Black	Download
2965JH	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.50	Black	Download
2965JJ	0.88	0.625	0.625	Thermoset	10-24	Female Insert	0.375	Black	Download
2965JL	0.88	0.94	0.625	Thermoset	10-32	Projecting Stud	0.25	Black	Download
2965JM	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.375	Black	Download
2965JN	0.88	0.95	0.625	Thermoset	10-32	Projecting Stud	0.75	Black	Download
2965JT	0.88	0.625	0.625	Thermoset	1/4-20	Projecting Stud	0.75	Black	Download
2965JV	0.88	0.625	0.625	Thermoset	1/4-20	Projecting Stud	0.50	Black	Download
2965KD	0.88	0.625	0.625	Thermoset	5/16-18	Projecting Stud	1.00	Black	Download
2965KG	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.75	Black	Download
2965KM	0.88	0.75	0.625	Thermoset	10-24	Female Insert	0.375	Black	Download
2965KN	0.88	0.625	0.625	Thermoset	10-32	Projecting Stud	1.00	Black	Download
2965LC	0.88	0.625	0.625	Thermoset	5/16-18	Projecting Stud	0.875	Black	Download
2965LE	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	1.25	Black	Download
2965LG	0.88	0.75	0.625	Thermoset	10-32	Projecting Stud	1.25	Black	Download
2965LJ	0.88	0.5	0.625	Thermoset	5/16-18	Projecting Stud	0.75	Black	Download
2965LM	0.88	0.625	0.625	Thermoset	1/4-20	Projecting Stud	2	Black	Download
2965LP	0.88	0.625	0.625	Thermoset	1/4-20	Tapped Thread	0.375	White	Download
2965LV	0.88	0.625	0.625	Thermoset	1/4-20	Female Insert	0.375	White	Download
2965MB	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	1.00	Black	Download
2965MG	22mm	19mm	16mm	Thermoset	M6	Projecting Stud	35mm	Black	Download
2965NQ	0.88	0.625	0.625	Thermoset	5/16-18	Projecting Stud	1.75	Black	Download
2965NS	0.88	0.75	0.625	Thermoset	10-24	Projecting Stud	1.00	Black	Download
2965NU	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.25	Black	Download
2965NV	0.88	0.625	0.625	Thermoset	10-32	Projecting Stud	1.00	Black	Download
2965NY	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.625	Black	Download
2965PC	0.88	0.75	0.625	Thermoset	10-24	Female Insert	0.375	Black	Download
2965PG	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.25	Black	Download
2965PH	0.88	0.5	0.625	Thermoset	0.25	Plain Molded Hole	0.44	Black	Download
2965PJ	0.88	0.625	0.625	Thermoset	1/4-20	Female Insert	0.375	Green	Download
2965PU	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	0.50	Black	Download
2965PV	0.88	0.625	0.625	Thermoset	5/16-18	Projecting Stud	2.25	Black	Download
2965PW	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.75	Black	Download
2965QA	22mm	19mm	16mm	Thermoset	M4x0.7	Female Insert	10mm	Black	Download
2965QB	22mm	19mm	16mm	Thermoset	M6x1	Female Insert	12mm	Black	Download
2965QC	22mm	19mm	16mm	Thermoset	M4x0.7	Projecting Stud	10mm	Black	Download
2965QD	22mm	19mm	16mm	Thermoset	M4x0.7	Projecting Stud	20mm	Black	Download

2965QE	22mm	19mm	16mm	Thermoset	M6x1	Projecting Stud	20mm	Black	Download
2965QF	22mm	19mm	16mm	Thermoset	M6x1	Projecting Stud	30mm	Black	Download

PRODUCTS

- [Knobs](#)
- [Handles](#)
- [Electronic Enclosures](#)
- [Hex Hybrid Standoffs](#)
- [Two-Shot / Soft Touch](#)
- [Frac Balls](#)
- [Cable Glands](#)
- [Rubber Grommets](#)
- [Custom Molding](#)

RESOURCES

- [Engineering Specifications](#)
- [Distributor Listing](#)
- [Sales Representative Listing](#)

COMPANY

- [About Us](#)
- [Capabilities](#)
- [Certifications](#)
- [Contact Us](#)
- [Blog](#)
- [Careers](#)

QUESTIONS ?

1 + 1 = *