


« Clamping Knobs

Three Arm Clamping Knobs

Series #3041

- ▶ Clamping knobs are available in different materials, thermoplastic, and phenolic for a multiple of applications.
- ▶ A variety of shapes and diameters with plain, tapped bosses or with studs are available with standard threads to fit the application.
- ▶ Perfect for the industrial machinery, medical, general equipment and other industrial applications.
- ▶ Knobs can be decorated or customized to your specific need.
- ▶ Davies Molding is pleased to introduce our series of soft touch knobs and handles. Our soft touch parts are molded with a soft thermoplastic overmolded "rubber" top with a tough thermoplastic body underneath. The soft feel of the knob provides a comfortable touch with a sure grip.
- ▶ Colors available upon request.
- ▶ Please note: Not all variations available are listed below. Please [contact customer service](#) to inquire about all available options.

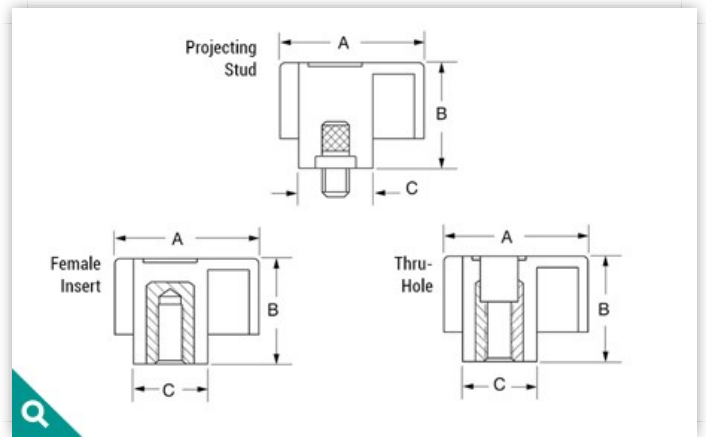

CHECK INVENTORY

REQUEST A QUOTE

Item #	Diameter A	Height B	Hub C	Material Type	Mounting Diameter	Mounting Type	Thread Length/Depth	Color	Product Drawing
3041	2	1.00	0.75	Thermoplastic	1/4-20	Female Insert	0.50	BLACK	Download
3041-A	2	1.00	0.75	Thermoplastic	5/16-18	Female Insert	0.50	BLACK	Download
3041-B	2	1.00	0.75	Thermoplastic	3/8-16	Female Insert	0.50	BLACK	Download
3041-C	2	1.00	0.75	Thermoplastic	3/8-24	Female Insert	0.625	BLACK	Download
3041-D	2	1.00	0.75	Thermoplastic	1/4-20	Projecting Stud	0.56	BLACK	Download
3041-E	2	1.00	0.75	Thermoplastic	5/16-18	Projecting Stud	0.75	BLACK	Download
3041-F	2	1.00	0.75	Thermoplastic	3/8-16	Projecting Stud	0.75	BLACK	Download
3041-J	2	1.00	0.75	Thermoplastic	1/4-20	Projecting Stud	0.50	BLACK	Download
3041-L	2	1.00	0.75	Thermoplastic	5/16-18	Projecting Stud	1.00	BLACK	Download
3041-M	2	1.00	0.75	Thermoplastic	5/16-18	Thru-Hole		BLACK	Download
3041-Q	2	1.00	0.75	Thermoplastic	3/8-16	Projecting Stud	1.00	BLACK	Download
3041-U	2	1.00	0.75	Thermoplastic	5/16-18	Projecting Stud	0.50	BLACK	Download
3041-W	2	1.00	0.75	Thermoplastic	3/8-16	Thru-Hole		BLACK	Download
3041-X	2	1.00	0.75	Thermoplastic	1/4-20	Thru-Hole		BLACK	Download
3041AA	2	1.00	0.75	Thermoplastic	1/4-20	Projecting Stud	1.00	BLACK	Download
3041AF	2	1.00	0.75	Thermoplastic	5/16-18	Projecting Stud	1.75	BLACK	Download
3041AG	2	1.00	0.75	Thermoplastic	5/16-18	Thru-Hole		BLACK	Download
3041AH	2	1.00	0.75	Thermoplastic	3/8-16	Projecting Stud	2.50	BLACK	Download

3041AM	2	1.00	0.75	Thermoplastic	3/8-16	Projecting Stud	2	BLACK	Download
3041AS	2	1.00	0.75	Thermoplastic	3/8-16	Projecting Stud	0.50	BLACK	Download

PRODUCTS

- [Knobs](#)
- [Handles](#)
- [Electronic Enclosures](#)
- [Hex Hybrid Standoffs](#)
- [Two-Shot / Soft Touch](#)
- [Frac Balls](#)
- [Cable Glands](#)
- [Rubber Grommets](#)
- [Custom Molding](#)

RESOURCES

- [Engineering Specifications](#)
- [Distributor Listing](#)
- [Sales Representative Listing](#)

COMPANY

- [About Us](#)
- [Capabilities](#)
- [Certifications](#)
- [Contact Us](#)
- [Blog](#)
- [Careers](#)

QUESTIONS ?

questions / comments

1 + 1 = *

SEND