



PMRL125 (.230" MOUNTING HOLE)

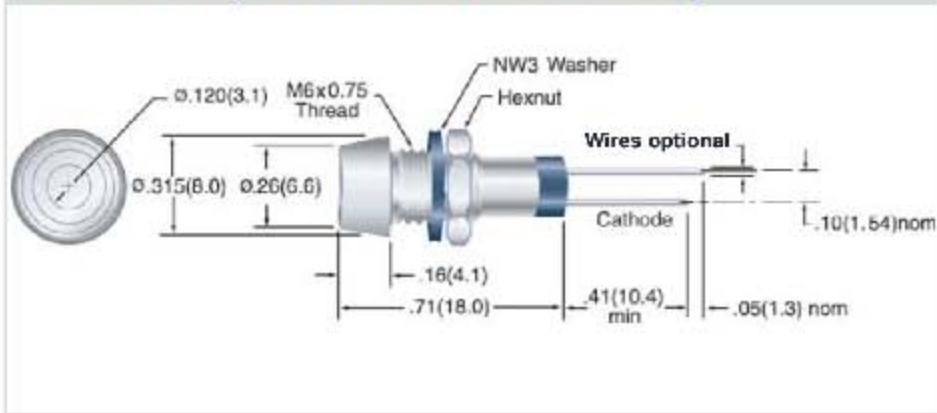

- Reflective Chrome-Plated Housing
- Mounting Hardware Provided

LED Color	Voltage	Design Current
Red	5VDC	15-22mA
Amber	6VDC	15-21mA
Green	12VDC	15-20mA
Blue	15VDC	15-20mA
Cool White	24VDC	15-17mA
Warm White	28VDC	15-16.5mA
	48VDC	9.5-15mA
	60VDC	7mA-9mA
	120VAC	3.5mA

PMRL200 (.312" MOUNTING HOLE)

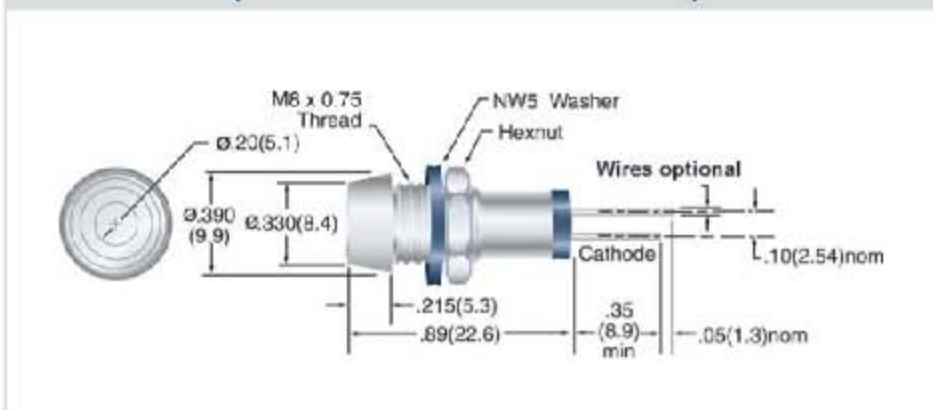

- Reflective Chrome-Plated Housing
- Mounting Hardware Provided



All dimensions are in inches (mm)

Tolerances: .xx"(.x) $\pm .025$ "/(.63) / .xxx"(.xx) $\pm .010$ "(.25)
 Specifications are subject to change without notice.